



SIVACON, swing frame, for the installation of 19" devices, load capacity up to 200 kg, H: 2000 mm, electrically zinc-plated

Model	
product brand name	SIVACON
design of the product	For installation of 19" units, screwed
design of the surface	Galvanized
design of the product EMC version	No
material	steel

Appearance	
RAL color number	RAL 7035
product component	
• ventilation	No

Mechanical Design	
height	2 000 mm
net weight	19 000 g

Approvals Certificates		
General Product Approval	Test Certificates	other



[Special Test Certificate](#)

[Confirmation](#)

[Miscellaneous](#)

other	Environment
-------	-------------


[Miscellaneous](#)



[Environmental Confirmations](#)

Further information

Information on the packaging
<https://support.industry.siemens.com/cs/ww/en/view/109813875>
 Information- and Downloadcenter (Catalogs, Brochures,...)
<http://www.siemens.com/lowvoltage/catalogs>
 Industry Mall (Online ordering system)
<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8MF1000-2AR02-4>
 Service&Support (Manuals, Certificates, Characteristics, FAQs,...)
<https://support.industry.siemens.com/cs/ww/en/ps/8MF1000-2AR02-4>
 Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)
http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=8MF1000-2AR02-4
 CAx-Online-Generator
<http://www.siemens.com/cax>
 Tender specifications
<http://www.siemens.com/specifications>

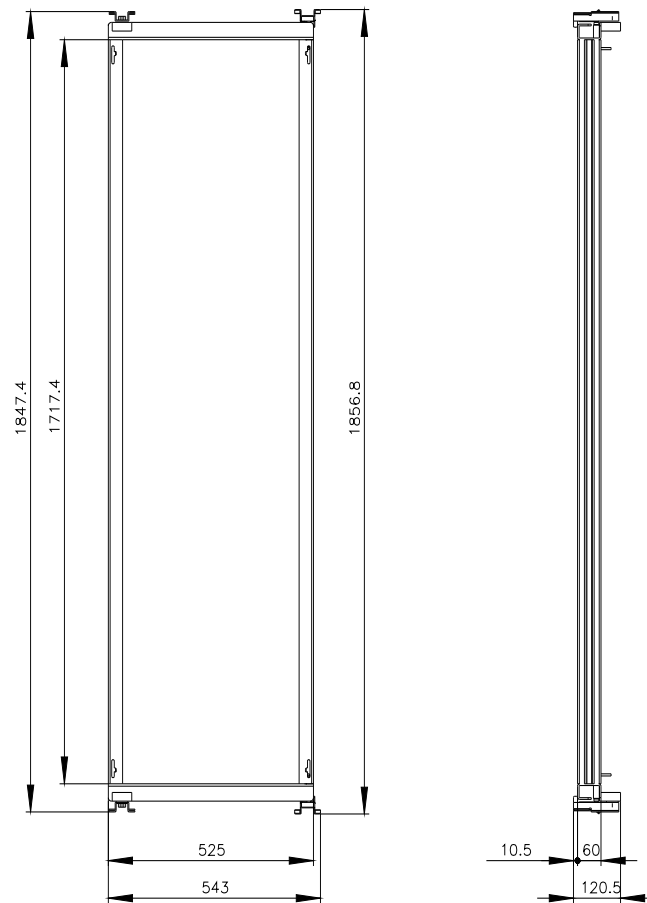

last modified:

4/13/2025 

