




Digital hygrometer with dew point indicator

Rev.1213



- **Functions:**
ambient temperature
relative air humidity
dew point temperature
- Short measuring time thanks **rapid sensor technology**
- **Min/Max display:** The smallest or largest measured value can be displayed, as needed.
- Measurement display in **°C** or **°F** selectable
- Toggle ambient temperature / dew point temperature
- **Practical device** for monitoring room climate
- Clip holder

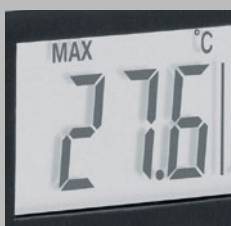

Min/Max display



Rapid sensor technology



Clip holder

TECHNICAL DATA	
AMBIENT TEMPERATURE	-10°C ... 50°C ACCURACY ±1 °C
RELATIVE AIR HUMIDITY	20%rH ... 99%rH ACCURACY ±5%rH (25%rH...85%rH)
DEW POINT TEMPERATURE	-28.5°C ... 47.5°C ACCURACY ±2 °C
OPERATING TEMPERATURE	-10°C ... 50°C
POWER SUPPLY	1 x LR44 button cell
DIMENSIONS (W x H x D)	138 x 27 x 19 mm
WEIGHT (incl. battery)	38 g



ClimaPilot
+ battery

Packing dimension (W x H x D)

-

ARTICLE	ARTICLE NO	EAN-CODE	PU
ClimaPilot	082.034A	4 021563 687886	5

