



Product data sheet

Power tools for trade & industry

Cordless Nailer

PRO GNH18V-50-2M



Gasless, cordless 18 ga (1.2 mm) brad nail gun with pneumatic performance and bump fire mode

The most important data

Nail length	16 – 50 mm
Nail diameter	1.2 mm
Triggering system	Full sequential actuation + contact actuation with automatic reversion

Part Number 0 601 482 C01

Technical data

Technical data

Collation angle	0 °
Nail diameter	1.2 mm
Nail length	16 – 50 mm
Nail/Staple type	Brad nail
Triggering system	Full sequential actuation + contact actuation with automatic reversion
Weight excl. battery	2.4 kg
Battery voltage	18.0 V
Magazine capacity	110 Pcs
Packaging dimensions (width x length x height)	360 x 444 x 253 mm
Compatible nails/staples	Bosch nails, Other
BITURBO	No

Noise/vibration information

Total vibration values

Vibration emission value ah	2.6 m/s ²
Uncertainty K	1.5 m/s ²

**BOSCH**


Invented for life

Product data sheet

Power tools for trade & industry

Advantages:

- Cordless freedom with the power of a pneumatic tool – without compressors, gas cartridges, or cords
- Gentle on your wrist and lungs thanks to very low recoil and gasless operation
- Single- and contact-activation mode, stepless depth adjustment and dry fire lockout for convenient usage in all situations

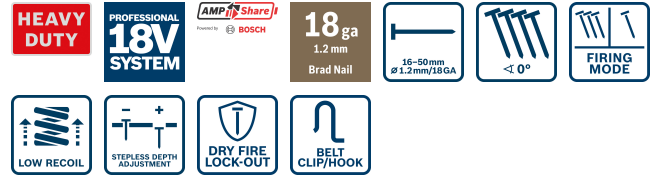

You can find more information about the deviations in the following link: <https://www.bosch-professional.com/gb/en/wac/>

