


# sub-base VABS-S4-1S-G14-B-K2

Part number: 541065

FESTO

with port pattern according to standard 15407/-2.

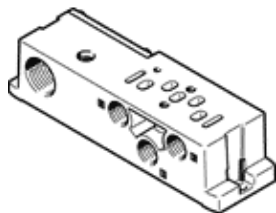

## Data sheet

| Feature                                 | Value   |
|---|---|
| Width                                   | 26 mm   |
| Based on the standard                   | ISO 15407-2   |
| Assembly position                       | Any   |
| Pilot air supply                        | Internal  |
| Operating pressure                      | -0.9 ... 10 bar   |
| Operating voltage range AC              | 110 V   |
| Operating voltage range DC              | 24 V  |
| Surge strength                          | 4 kV  |
| Acceptable current load at 40°C         | 2 A   |
| Degree of contamination                 | 3   |
| CE mark (see declaration of conformity) | to EU directive low-voltage devices   |
| Operating medium                        | Compressed air in accordance with ISO8573-1:2010 [7:4:4]                    |
| Note on operating and pilot medium      | Lubricated operation possible (subsequently required for further operation) |
| Corrosion resistance classification CRC | 0 - No corrosion stress   |
| Protection class                        | IP65<br>NEMA 4<br>in assembled condition                                    |
| Ambient temperature                     | -5 ... 50 °C  |
| Product weight                          | 302 g   |
| Mounting type                           | with through hole<br>according to ISO 15407-2                               |
| Materials note                          | Conforms to RoHS  |
| Material of connecting plate            | Aluminium die cast  |