


Geberit Mapress Stainless Steel elbow adaptor 90° with male thread



Example image

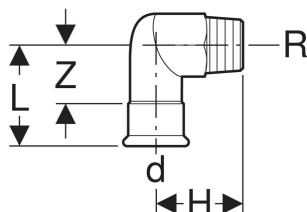

APPLICATION PURPOSES

- For cold and hot potable water
- For cooling and heating water without antifreeze agent
- For cooling and heating water with antifreeze agent
- For district heating water $\leq 120\text{ }^{\circ}\text{C}$
- For saturated steam $\leq 120\text{ }^{\circ}\text{C}$
- For service water and process water
- For treated water
- For rainwater with a pH value ≥ 5.5
- For grey and black water with a pH value ≥ 5.5
- For extinguishing water (wet)
- For extinguishing water (wet/dry, dry)
- For sprinklers (wet)
- For chemicals and technical liquids
- For compressed air (oil purity class 0–3)
- For negative pressure
- For inert gases (e.g. nitrogen)
- For industrial gases (e.g. acetylene, shielding gases)
- For technical building systems, industry and shipbuilding

CHARACTERISTICS

- Pressing indicator
- Leaky if unpressed
- Seal ring made of CIIR, black
- Pressing socket with transparent protection plug

TECHNICAL DATA

Product material CrNiMo steel 1.4401 (EN 10088)

Art. no.	DN	d, ø mm	R "	arc °	L cm	H cm	Z cm
33833	12 / 15	15	1/2	90	5.7	3.7	3.7
33834	15	18	1/2	90	5.7	3.9	3.7
33835	20	22	3/4	90	6	4.6	3.9
33836	25	28	1	90	6.7	5.4	4.4

Art. no.	DN	d _ø mm	R "	arc °	L cm	H cm	Z cm
33837	32	35	1 1/4	90	7.5	6.3	4.9
33838	40	42	1 1/2	90	8.3	6.7	5.3
33839	50	54	2	90	9.4	7.8	5.9