

Datasheet

RS PRO VINYL-INSULATED DOUBLE CRIMP FEMALE DISCONNECTORS

Stock number: 178-8282

MAXIMUM ELECTRIC CURRENT:

| | | |
|--------|----|----|
| A.W.G. | 16 | 14 |
| AMP. | 10 | 15 |

MAXIMUM ELECTRICAL RATING: 105° C 600 VOLTS MAX.


INSULATION MATERIAL: VINYL

TERMINAL MATERIAL: BRASS

INSULATION COLOR: BLUE

DOUBLE CRIMP: WITH COPPER SLEEVE ON BARREL

TERMINAL BARREL I.D.: C=2.3MM

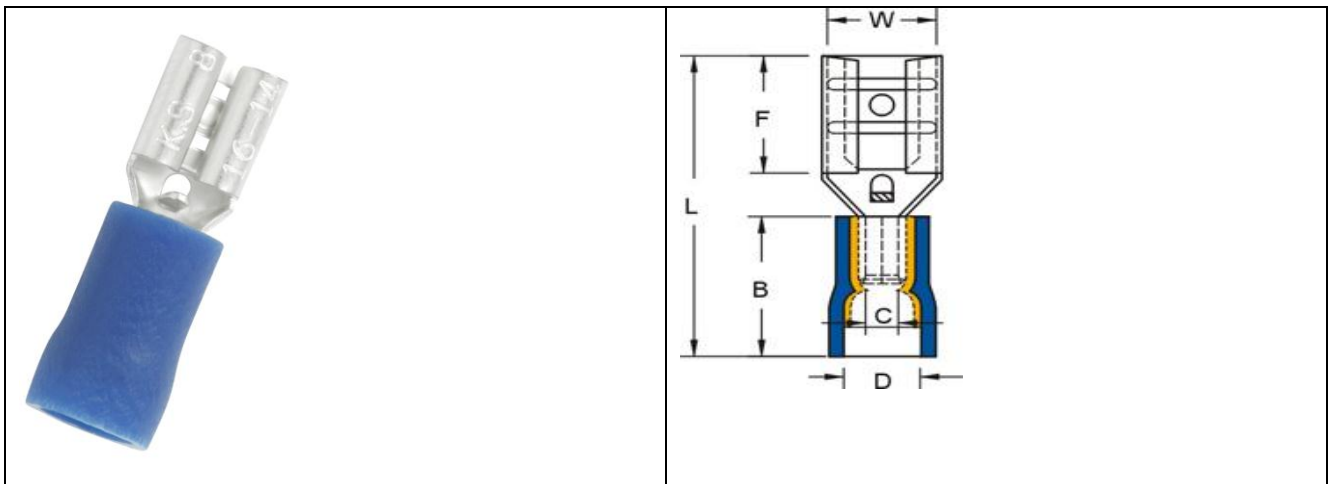

| WIRE RANGE A.W.G. mm ² | ITEM NO. | NEMA TAB | DIMENSION inch(mm) | | | | | | |
|---|----------|-------------------------|--------------------|--------------|---------------|---------------|----------------|---------------|--|
| | | | W | F | L | B | D | T | |
| 16-14 A.W.G. 1.5-2.5 mm ² | 178-8282 | .032X.187 (0.8X4.75) | 0.197 5 | 0.252 6.4 | 0.764 19.4 | 0.413 10.5 | 0.185 4.700 | 0.014 0.35 | |