

FEATURES

- Closed slot design
- Self-adhesive
- Supplied with a coupling kit
- 304 Stainless Steel
- 3m length

RS PRO Grey Industrial Trunking - Closed Slot, W50 mm x D50mm, L3m, 304 Stainless Steel

RS Stock No.: 471-11647



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

Brought to you by RS Pro, A range of trunking suitable for high levels of cable management. Due to stainless steel material, this strong and sturdy trunking is an excellent addition of cable protection for your application. The closed slot design fully protects the cable from accident damage and can be mounted in a suitable position. All models are highly reliable and excellent quality.

General Specifications

Trunking/Chain Type	Industrial Trunking
Material	304 Stainless Steel
Colour	Grey
Type of Fastening	Self-adhesive

Mechanical Specifications


Length	1m
Width	50mm
Depth	50mm
Slot Type	Closed

Protection Category

IP Rating	IP4X / IPXXD
------------------	--------------

Approvals

Standards Met	UL
----------------------	----

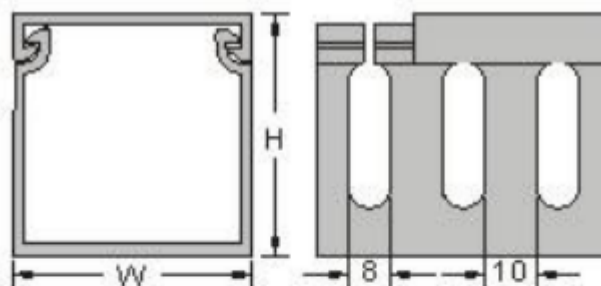

RS Article No	W(mm)	H(mm)	A	Slot	Length
301-1924	25	25	10	8mm	2M
301-1946	33	45	14		
301-1930	25	45	10		
301-1974	50	50	22.5		
301-1968	45	45	20		
301-1980	25	65	10		
301-2006	60	60	27.5		
301-1996	45	65	20		
301-2040	33	100	14		
301-2034	72	64	33.5		
879-3713	25	25	10		
879-3722	60	60	27.5	8mm	2M
758-9260	15	25	5		