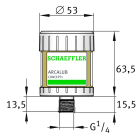


**ARCALUB-C1-60-REFILLABLE** [↗](#)

Automatic lubricator CONCEPT

CONCEPT1, Single-point lubricator (125 cm³, empty)

Technical information

**Your current product variant**

Drive System	HG	Hydrogen gas development cell
Lubricant volume	V60	60 cm ³

Technical data

	Gas drive	Functional principle
V _{Lub}	60 cm ³	Lubricant volume
P _{op}	5 bar	Operating pressure, max.
	≤ NLGI 2 (suitability test required)	Lubricant
n _{out}	1	Number of outlets
	1	Number of lubrication points: direct
U _{op}	—	Operating voltage
	IP68	Protection class
	Polyethylenterephthalat (PET)	Housing material
t _{min}	-20 °C	Operating temperature, min.
t _{max}	55 °C	Operating temperature, max.
	arbitrary	Mounting position
	G $\frac{1}{4}$	Connection thread
	79 x 53 x 53	Dimensions (mm)
≈m	66 g	Weight