

Double-ended ring spanners, imperial, extra long

220a



Product no.	41432428
GTIN	4018754156795
Model	220a 3/8 x 7/16



Label.

Double-ended ring spanner Size 3/8 x 7/16 " L.250mm

Properties.

- **imperial, differing** end sizes
- cranked 15°
- bi-hex with AS-Drive profile
- extra long design for less effort with constant torque
- suitable for working in confined spaces
- durable, slim and lightweight design
- high flexural strength due to double-T profile
- STAHLWILLE's rounded finish ensures a non-slip, pleasant feel
- HPQ® high performance steel, chrome-plated
- SAE AS 954-E (test values)

Benefits.

High quality double-ended ring spanner with an extra long design for better power transmission.

Product highlights.



Extra-long design.

The spanner is ideal for working on hard-to-reach screw points due to its extended design and enables high torques for better power transmission when tightening.

Technologies and features.



High Performance Quality (HPQ®)

Our HPQ® tool is made of wear-resistant high-performance steel, yet is thin-walled and lightweight. It withstands high torques and is ideal for work in confined spaces such as turbines.



Anti-Slip-Drive


The special AS-Drive profile makes high force transmission to the flats of bolts and nuts possible without damaging them. This also prevents stripping of the screw head.



Thin-walled rings

The thin-walled diameter of our rings makes it easier to work in confined spaces. The ring wall is deeper than standard nuts, which prevents jamming.

Technical drawing.

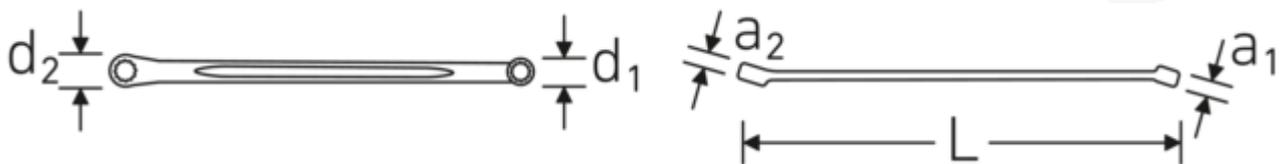

Technical attributes.

a1	8 mm
a2	8,7 mm
Drive profile	bi-hex AS-Drive
d1	14 mm
d2	16 mm
Length mm (L)	250 mm

Logistics data.

Depth mm (IFS)	250
Width mm (IFS)	16
Height mm (IFS)	11
WEEE/ElektroG	nicht ear-pflichtig
Length (packaged, mm)	270
Width (packaged, mm)	55
Height (packaging, mm)	14

Alloy	HPQ® high performance steel	Volume (packaged, dm3)	0.2079 dm3
Surface	chrome-plated	Product no.	41432428
Ring position	15 °	Weight (gross, kg)	0,403
Size 1 [inch]	3/8 "	Weight PAP (kg)	0,000
Size 2 [inch]	7/16 "	Weight PVC (kg)	0,004
		GTIN	4018754156795
		Country of origin AWR	GERMANY
		Region of origin	Nordrhein-Westfalen
		Customs tariff no.	82041100
		Packing standard	5
		Weight (g)	79 g

Variants.

Product no.	Model No. (ERP)	Description	GTIN
41431416	220a 7/32 x 1/4	Double-ended ring spanner Size 7/32 x 1/4 " L.184mm	4018754156771
41431620	220a 1/4 x 5/16	Double-ended ring spanner Size 1/4 x 5/16 " L.205mm	4018754156788
41432428	220a 3/8 x 7/16	Double-ended ring spanner Size 3/8 x 7/16 " L.250mm	4018754156795
41433234	220a 1/2 x 9/16	Double-ended ring spanner Size 1/2 x 9/16 " L.290mm	4018754156801
41433640	220a 5/8 x 3/4	Double-ended ring spanner Size 5/8 x 3/4 " L.363mm	4018754156818
41433840	220a 11/16 x 3/4	Double-ended ring spanner Size 11/16 x 3/4 " L.365mm	4018754156825

GTIN.



STAHLWILLE Eduard Wille GmbH

Lindenallee 27 · 42349 Wuppertal · Germany · Phone: +49 202 4791-0

info@stahlwille.de · www.stahlwille.com

© STAHLWILLE Eduard Wille GmbH, Wuppertal