



Socket

60

Product no. **06010070**
GTIN **4018754009978**
Model **60 70**



Label. 1 " Socket Size 70mm L.110mm

Properties.

- hex
- 1" internal square drive
- Chrome Alloy Steel, chrome-plated
- DIN 3124


Technologies and features.



High Performance Quality (HPQ®)

Our HPQ® tool is made of wear-resistant high-performance steel, yet is thin-walled and lightweight. It withstands high torques and is ideal for work in confined spaces such as turbines.

Technical drawing.

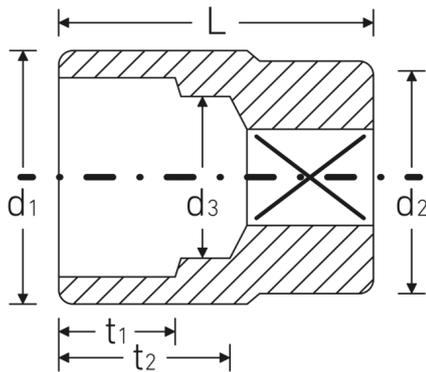

Technical attributes.

Drive profile	hex
Square drive inner (inch)	1 "
d1	94 mm
d2	60 mm
d3	63 mm
DIN	DIN 3124
Length mm (L)	110 mm
Size [mm]	70 mm
t1	42 mm
t2	72,5 mm

Logistics data.

Depth mm (IFS)	111
Width mm (IFS)	94
Height mm (IFS)	94
WEEE/ElektroG	nicht ear-pflichtig
Length (packaged, mm)	112
Width (packaged, mm)	95
Height (packaging, mm)	95
Volume (packaged, dm3)	1.0108 dm3
Product no.	06010070
Weight (gross, kg)	2,210
Weight PAP (kg)	0,000
Weight PVC (kg)	0,000
GTIN	4018754009978
Country of origin AWR	GERMANY
Region of origin	Nordrhein-Westfalen
Customs tariff no.	82042000
Packing standard	1
Weight (g)	2210 g

Variants.

Product no.	Model No. (ERP)	Description	GTIN
06010065	60 65	1 " Socket Size 65mm L.105mm	4018754009961
06010070	60 70	1 " Socket Size 70mm L.110mm	4018754009978
06010075	60 75	1 " Socket Size 75mm L.115mm	4018754009985

06010080

60 80

1 " Socket Size 80mm L.120mm

4018754009992

GTIN.



STAHLWILLE Eduard Wille GmbH

Lindenallee 27 · 42349 Wuppertal · Germany · Phone: +49 202 4791-0

info@stahlwille.de · www.stahlwille.com

© STAHLWILLE Eduard Wille GmbH, Wuppertal