


<b>Universe</b>	Professional
<b>Type</b>	Verticality
<b>Category</b>	Kits
<b>Subcategory</b>	Temporary horizontal lifelines and fall arrest kits

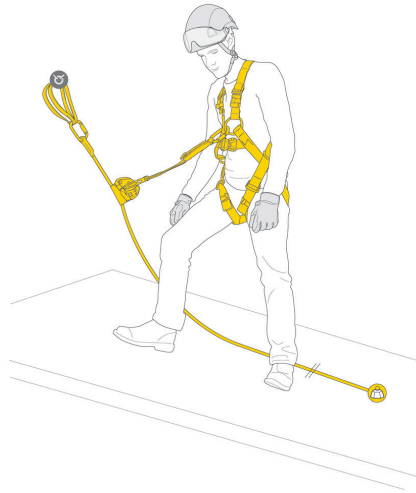

## ASAP® LOCK FALL ARREST KIT

ASAP LOCK FALL ARREST KIT is a ready-to-use kit designed to protect against falls from height. It contains a NEWTON fall arrest harness, an ASAP LOCK mobile fall arrester with locking function, an ASAP'SORBBER energy absorber, two OK TRIACT-LOCK carabiners, an ANNEAU open sling, an AXIS 11 mm rope with sewn termination, a weight, and a BUCKET bag. The kit is available in two sizes and four lengths.

---

**Short Description** Kit for protection against falls with NEWTON harness and ASAP LOCK mobile fall arrester

---

**Selling Points**

- Simple to use, and effective:
  - NEWTON harness equipped with a sternal FAST automatic buckle that allows the harness to be opened and closed simply and quickly
  - ASAP LOCK mobile fall arrester moves up or down the rope without any manual manipulation of the device. The integrated locking function allows the user to immobilize the device in order to reduce the length of a fall
  - pre-assembled kit for a system that is ready to use and that limits the risk of assembly error
  - weight that facilitates rope glide in the ASAP LOCK on the first few meters
  - BUCKET bag allows the kit to be stored and its contents identified
- Contents of kit:
  - a NEWTON fall arrest harness (European version)
  - an ASAP LOCK mobile fall arrester
  - a 40-cm ASAP'SORBBER energy absorber (European version)
  - two OK TRIACT-LOCK carabiners
  - an ANNEAU 150 cm open sling
  - an AXIS 11 mm rope with sewn termination
  - a weight
  - a 25-liter BUCKET bag
- Available in two harness sizes (sizes 1 and 2) and two rope lengths (10 and 20 meters)

---

**Specification**

---

**Specifications by reference**

Reference(s)	K094AA00	K094AA01	K094AA02	K094AA03
Rope length	10 m	10 m	20 m	20 m
Harness size	1	2	1	2
Weight	3505 g	3535 g	4305 g	4335 g
Made in	FR	FR	FR	FR
Guarantee	3 years	3 years	3 years	3 years
Packing	1	1	1	1
Case quantity	1	1	1	1
EAN	3342540822146	3342540822153	3342540822160	3342540822177

---

**Related product(s)** VERTEX® BEST  
VERTEX® VENT