


OGP-HPKG/6M

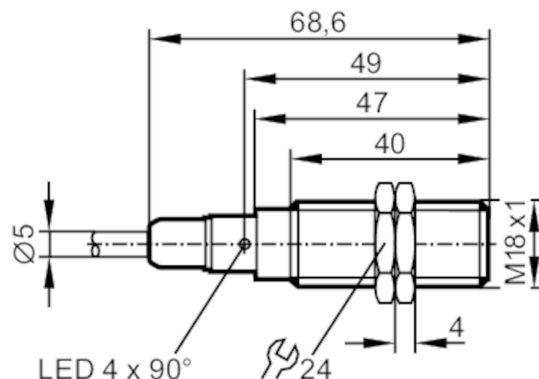

threaded type

Retro-reflective sensor


OGP303



Retro-reflective sensor

OGP-HPKG/6M

Operating conditions		
Ambient temperature	[°C]	-25...80
Protection		IP 65; IP 67; IP 68; IP 69K
Tests / approvals		
EMC		EN 60947-5-2
MTTF	[years]	500
Mechanical data		
Weight	[g]	257.5
Housing		threaded type
Dimensions	[mm]	M18 x 1 / L = 68.6
Thread designation		M18 x 1
Materials		housing: stainless steel (316L/1.4404); Sealing: EPDM
Lens material		PMMA
Displays / operating elements		
Display	switching status	1 x LED, yellow
Accessories		
Items supplied		lock nuts: 2
Remarks		
Remarks		operating voltage "supply class 2" according to cULus
Pack quantity		1 pcs.
Electrical connection		
Cable: 6 m, PVC; 3 x 0.34 mm ²		
Connection		

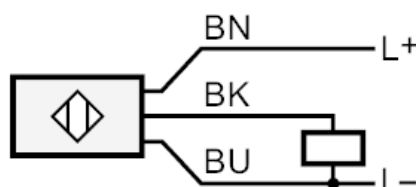

Core colours :
BK = black
BN = brown
BU = blue



Retro-reflective sensor

OGP-HPKG/6M

Diagrams and graphs

excess gain graph

