

Item # 1-2936 Model 29 Mechanical Stroke Counter



Model 29 Mechanical Stroke Counter

A 6 figure, general purpose heavy duty industrial stroke counter designed for high count rates and continuous operation even under the most adverse operating conditions. Corrosion resistant material and finishes. Large, easy-to-read numbers.

Specifications

Model No.	29
Display	6 Figures, white on black, 0.30 inch (7.6mm) high
Display Height	0.30 Inch
Display Height	7.6 mm
No. of Digits	6
Speed	1000 counts/minute
Operating Temperature	-15 to +140 °F
Operating Temperature	-26 to +60 °C
Reset Type	Knob
Weight	18 oz
Weight	510 gm
Operating Life	Beyond 100 million counts
Rotation	Top-coming
Shaft Extension	Right-hand
Shaft Diameter	0.25 Inch
Shaft Diameter	6.4 mm
Minimum Count Stroke	40 °
Maximum Count Stroke	70 °
Stock Availability	Yes
Mounting Hole Dia.	0.22 Inch
Mounting Hole Dia.	5.6 mm



Description

A 6 figure, general purpose heavy duty industrial stroke counter designed for high count rates and continuous operation even under the most adverse operating conditions. Corrosion resistant material and finishes. Large, easy-to-read numbers.

Features

- Heavy duty
- High count rates
- Corrosion resistant

Options

- Non-reset
- Double shaft extensions
- Special mounting bases
- Weatherized versions
- 1022-006S - additional spring
- 1255-004S - additional lever

Specifications

Figures: 6 figures, white on black, 0.30" [7.6mm] high
Reset: Knob or lock and key
Speed: 1,000 counts/minute
Rotation: Top-coming or top-going
Count Stroke: 40° Min. - 70° Max.



Shaft Extension: Right-hand or left-hand
Shaft Diameter: 0.25" [6.4mm]
Operating Life: Beyond 100 million counts
Temp. Range: -15°F to +140°F [-26°C to +60°C]
Weight: 18 oz. [510g]

Models	Description	Models	Description
1-2916	Left-hand, top-coming, standard reset knob	1-2946	Right-hand, top-going, standard reset knob
1-2926	Left-hand, top-going, standard reset knob	2-2936	Right-hand, top-coming, lock and key reset
1-2936	Right-hand, top-coming, standard reset knob	V1-2936	Right-hand, top-coming, standard reset knob, V-base


* Items in bold are normally in factory stock.

Dimensions

Right - Hand Shaft

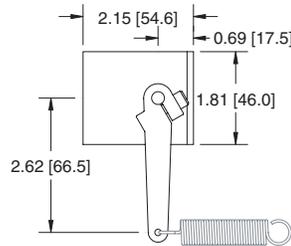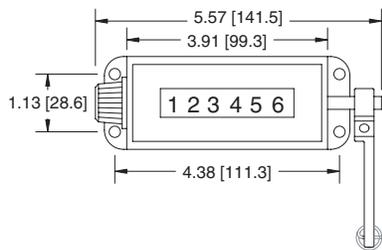


V - Mount

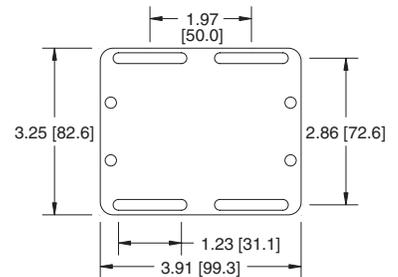


Mounting holes: 0.22" [5.6mm] Dia.

Applications

Punch presses

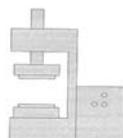

Shears

 

Cement trucks

