




Bravo


The first "Gel-Box" with integrated connectors!

- Ready to use, quick, re-enterable!
- For rigid or flexible insulated wires from 1 a 6 mm²
- Immediately energizable
- For straight & branch connections
- For 1 or 3 cores connections
- Small, compact and transparent
- No shelf life
- Halogen free and UV resistant

Electrical performance:
CEI EN 50393 as applicable
(testing under water head
of the accessory installed in a box)

Gel: UL 94-HB 

Operating voltage: 0,6 / 1kV

Operating temperature 

Installation temperature: 
-40°C / +50°C

Fully submersible 


Can be used underground 

IPX8
OFFICIALLY
TESTED | **IMQ**





Mini Bravo

Extra-flat mini box
with terminal block.

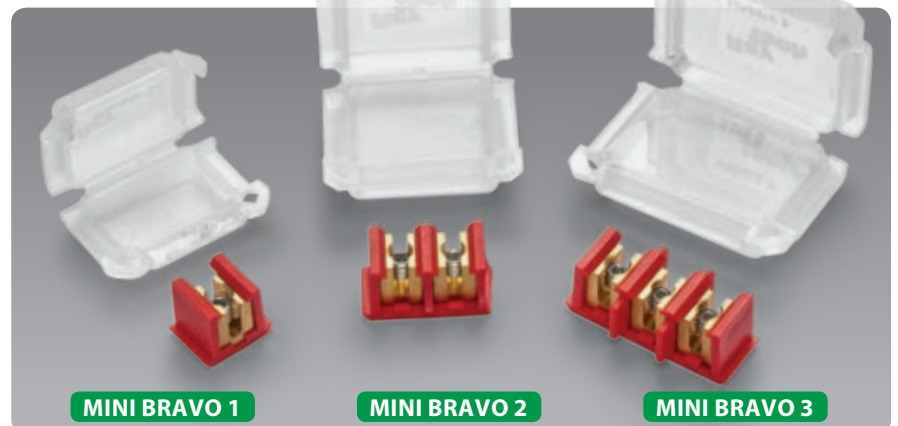



Bravo - Self-locking connection block.

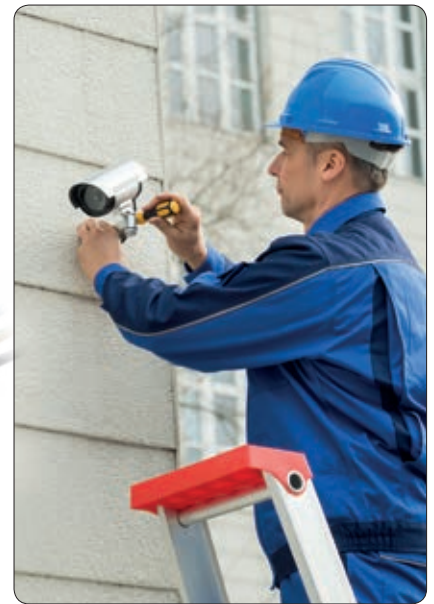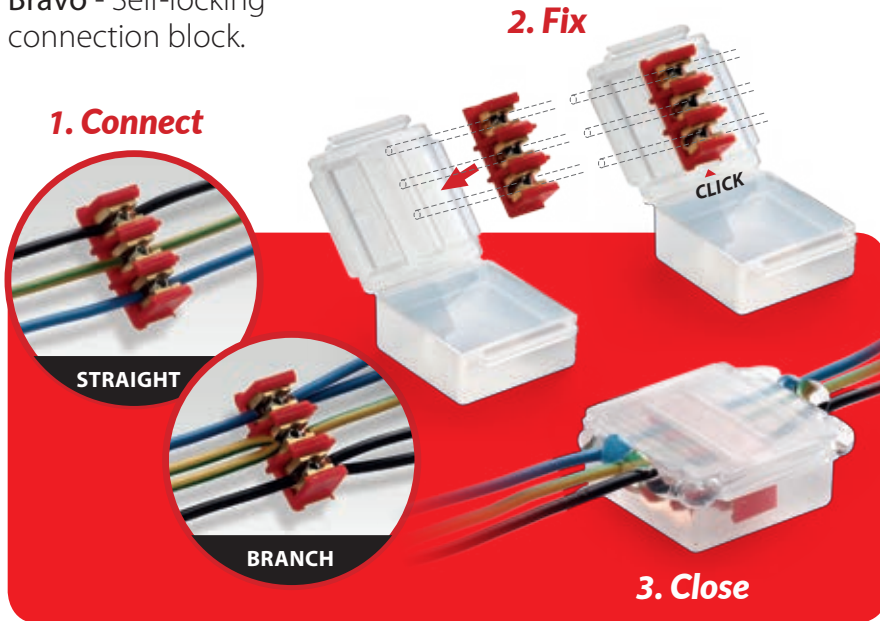

Bravo

Product	Formation and wires cross section		Pieces for package	A x B x C (mm)
	Straight or through (N° x mm ²)	Branch (N° x mm ²)		
Bravo 1-6	1 x 1 - 6	1 x 1 - 6	1 pcs/ Blister	50 x 29 x 22
Bravo 3-6	2 x 1 - 6 3 x 1 - 6	2 x 1 - 6 3 x 1 - 6	1 pcs/ Blister	53 x 49 x 22



Mini Bravo

Product	Formation and wires cross section		Pieces for package	A x B x C (mm)
	Straight or through (N° x mm ²)	Branch (N° x mm ²)		
Mini Bravo 1	1 x 1 - 4	1 x 1 - 4	3 pcs/ Blister	41 x 28 x 19
Mini Bravo 2	2 x 1 - 4	2 x 1 - 4	1 pcs/ Blister	45 x 37 x 24
Mini Bravo 3	3 x 1 - 4	3 x 1 - 4	1 pcs/ Blister	53 x 39 x 24

