




TAH1RM-10

Ratcheting Combination Wrench with Safety Spring 10 mm



PRODUCT DETAILS

- Larger, bi-directional, size marking for easy identification
- 12-Point Dynamic-Drive™ profile provides longer life for screws and nuts
- Chrome micro-matte finishing
- High-performance alloy steel
- Offset and slim head to get more accessibility
- Ratchet in the ring for high productivity application
- Suitable for working at height
- Permanent stainless steel sliding spring maintains user ergonomics and full functionality
- Colour plates with maximum weight for a right matching with the lanyard
- According to DROPS best practices

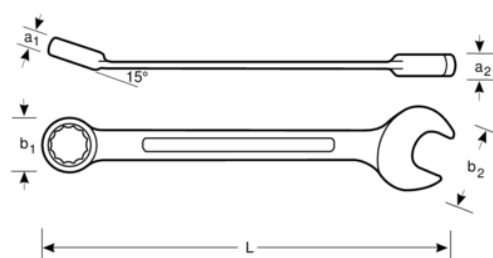

Follow the Fish!



PRODUCT ATTRIBUTES

Product		L	a1	a2	b1	b2	
TAH1RM-10	10 mm	159 mm	7.3 mm	5.3 mm	20 mm	20.8 mm	60 g

