


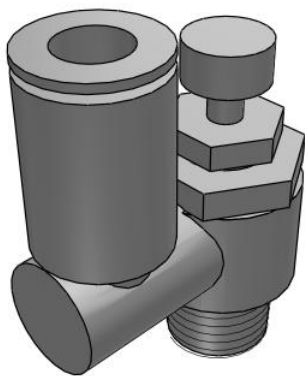

Universal - AS*3*1F AS2311F-02-08S

Datasheet


General series information

- Port Size: M3, M5, 10-32 UNF, 1/8, 1/4, 3/8, 1/2
- Applicable Tubing O.D.: Ø 3.2 to Ø 12 mm and Ø 1/8" to Ø 1/2"
- Operating Pressure Range: 0.1 to 1 MPa.

Standard specifications

Size	2 (1/8, 1/4 Basis)
Style	3 (Universal)
Control Method	1 (Meter-in)
Thread	M3, M5, U10/32, Rc
Port Size	02 (1/4)
Tube Size	Ø8
Option	S (Sealant)
Fixed Orifice	None
Made to Order	None
Lock Nut	Standard (Hexagon)
Weight	0.036 Kg

Dimensions

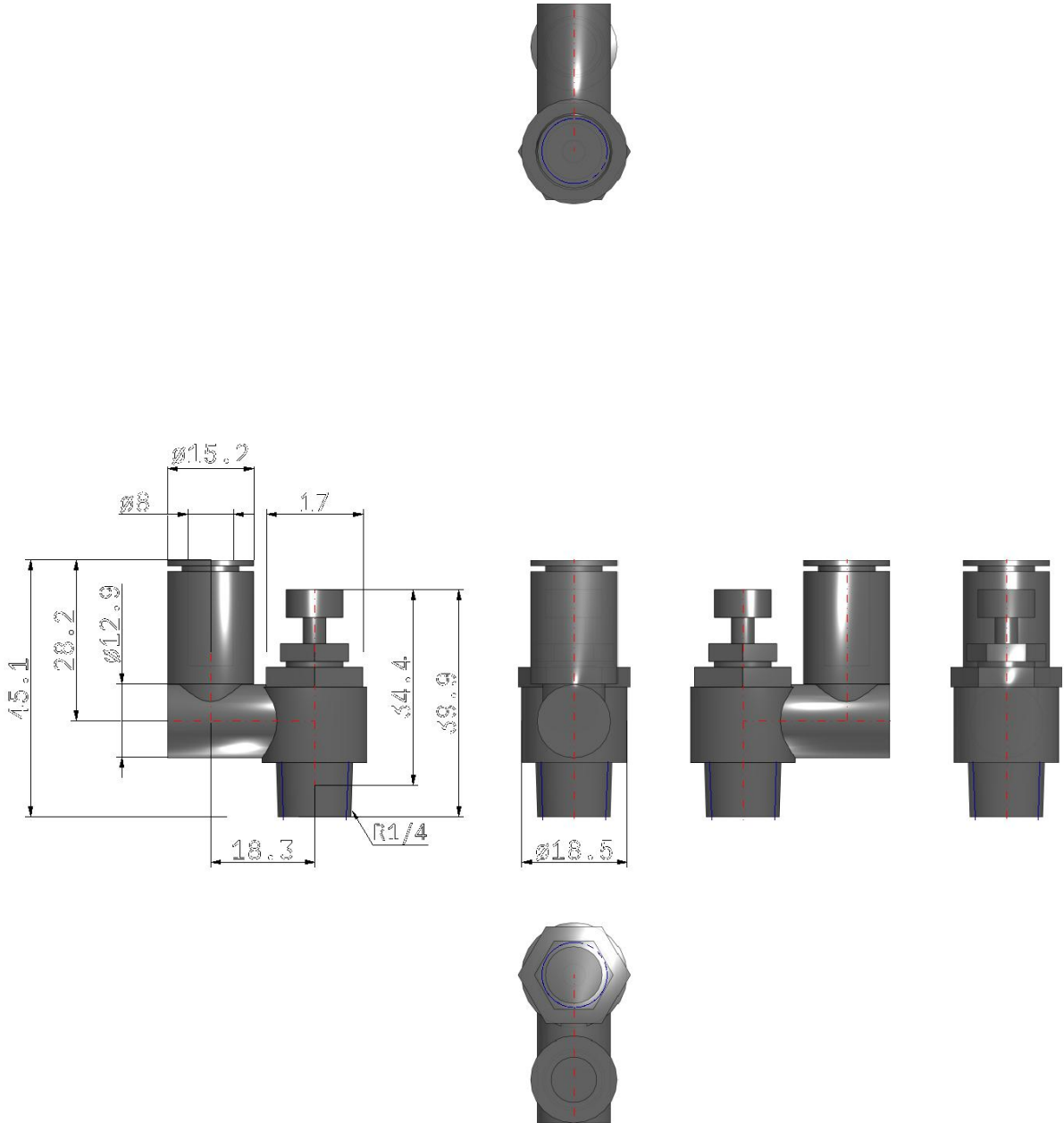

Additional information

Catalogue

[AS_2-3_1F-A_EU.pdf](#)