



Halogen Classic Candle B35

Halogen Classic 18W B22 240V B35 1CT

Philips Halogen Classic Candle light bulbs offer the classical shape you are used to. This new 'classic' gives high-quality light, is dimmable and starts immediately.

Product data

• General Characteristics

Cap-Base	BC [BC]
Bulb	B35 [B 35mm]
Bulb Finish	Clear
Burning Position	any [Any/Universal]
Life to 50% failures	2000 hr
Nominal Lifetime	2000 hr
Rated Lifetime	2000 hr
Rated Lifetime (years)	2 an

• Light Technical Characteristics

Colour Rendering Index	100 Ra8
Colour Temperature	2800 K
Colour Temperature Technical	2800 K
Lamp Luminous Flux	204 Lm
Rated Luminous Flux	204 Lm
Lamp Luminous Efficacy	11.1 Lm/W
LLMF - end nominal lifetime	80 (min) %

• Electrical Characteristics

Rated Wattage	18.0 W
Lamp Wattage	18 W
Technical Lamp Power	18 W
Power Factor	1 -
Voltage	240 V
Lamp Current	0.08 A
Dimmable	yes
Wattage Equivalent	23 W
Starting Time	0.0 s

Warm-up Time to 60% Light Outp	instant full light
--------------------------------	--------------------

• Environmental Characteristics

Energy Efficiency Label (EEL)	D
Energy consumption kWh/1000h	18 kWh

• Measuring Conditions

Switching cycle	8000X
-----------------	-------

• Luminaire Design Requirements

Cap-Base Temperature	130 (max) C
----------------------	-------------

• Product Dimensions

Overall Length C	94.5 (max) mm
Diameter D	36 (max) mm

• Product Data

Order code	862645 02
Full product code	872790086264502
Full product name	Halogen Classic 18W B22 240V B35 1CT
Order product name	Halogen Classic 18W B22 240V B35 1CT/15
Pieces per pack	1
Packing configuration	15
Packs per outerbox	15
Bar code on pack - EAN1	8727900862645

PHILIPS

 

Halogen Classic Candle B35

Bar code on
outerbox - EAN3
Logistic code(s) -
12NC

8718696462393
925693545503

Net weight per piece 24.500 gr

Dimensional drawing

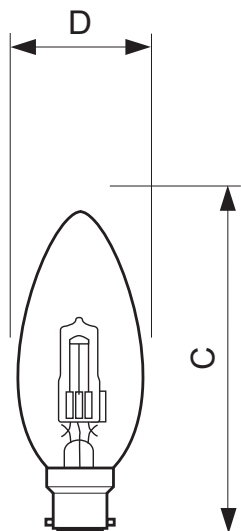

B22

Halogen Classic 18W B22 240V B35 1CT

Product	C (Max)	D (Max)
HalClass 18W B22 240V B35 CL	94.5	36



© 2015 Koninklijke Philips N.V. (Royal Philips)
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips N.V. (Royal Philips) or their respective owners.

www.philips.com/lighting

2015, September 24
data subject to change