


Datasheet

# ispot® Lozenge LED Bulkhead

**Description**

The ispot® Lozenge driverless bulkhead is the most advanced LED bulkhead on the market. It boasts an attractive ultra-thin design with a depth of only 36mm. The ispot® Lozenge driverless bulkhead is tamper proof with no visible screws on the front and tamper proof screws are hidden on the back. Available in Daylight and Warm White with a black or white finish.

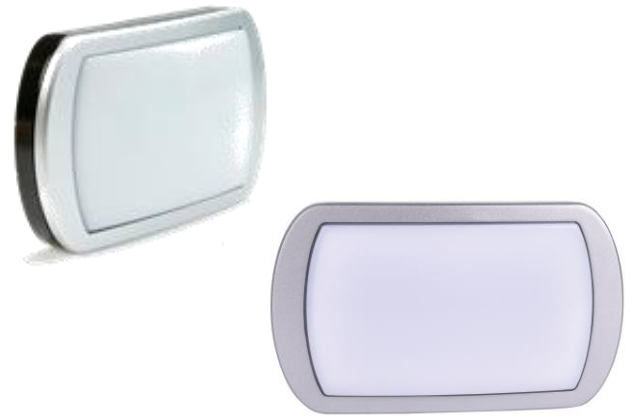

**Range**

- ispot® Lozenge 10W 5700K Black 9084060
- ispot® Lozenge 10W 5700K White 9084066
- ispot® Lozenge 20W 5700K Black 9084072
- ispot® Lozenge 20W 5700K White 9084079

**\*add suffix B or W for black/white finish**

**Dimensions (mm), Beam Angle & Lumens**

	Lumen Output	Beam Angle	Fitting Dimensions (L x H x D)
9084060	550lm	110°	220 x 130 x 36
9084066	550lm	110°	220 x 130 x 36
9084072	1100lm	110°	220 x 130 x 36
9084079	1100lm	110°	220 x 130 x 36

**Technical Specification**

- Voltage 220-240VAC~ 50/60Hz
- Lamp SMD LED
- Colour temp. 5700K / 3000K
- IP rating IP54

**Standards**

- BS EN 60598-1+A11
- BS EN 60598-2-1
- BS EN 60598-2-5
- BS EN 62471
- BS EN 62493
- BS EN 55015+A2
- BS EN 61547
- BS EN 61000-3-2+A2
- BS EN 61000-3-3