



## Datasheet

ENGLISH

Stock No: 209-080

# RS Pro Recessed Indicator Panel Mount, 8mm Mounting Hole Size, Blue LED



## Product Details

### LED Indicators, 8mm Mounting

Brought to you under the trusted RS Brand, these LED indicators have diffused epoxy lenses and a chrome bezel. The body features convenient solder tab terminals for ease of installation. LED indicators give a high level of brightness and a long life at low energy consumption, making them ideal for a variety of equipment applications.

#### Features and Benefits:


- 5mm tinted diffused epoxy lens
- Bright satin or black chrome brass housing available in range
- Recessed or prominent bezel style available in range
- 0.11in. (2.8 x 0.8mm) terminals, except tri-colour variants which have 2x0.5mm

#### Note

These LED indicators should not be operated without a suitable series resistor or other current-limiting device

#### Supplied with

fixing nut and washer

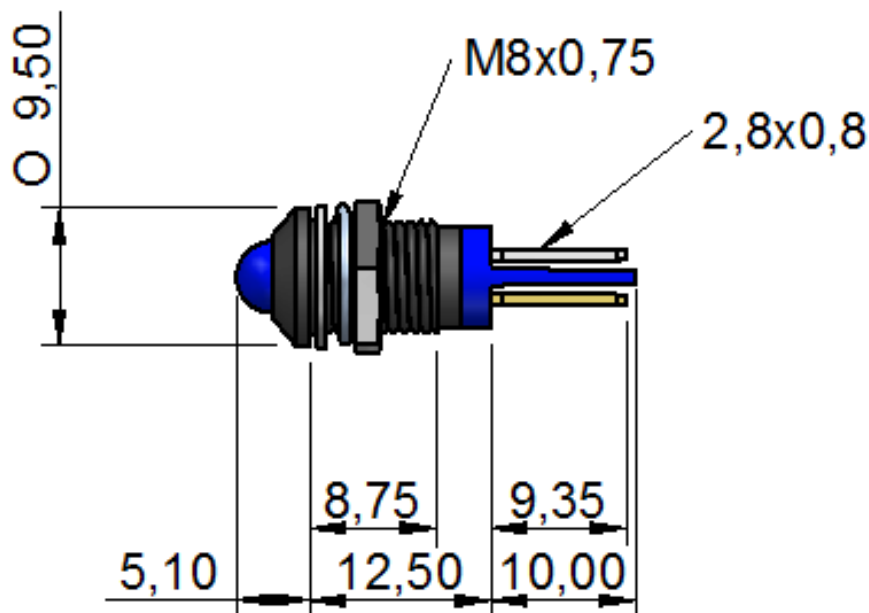

LED/Multiled	LED	Optimum voltage (V)	2Vdc	Intensity	90mcd@20mA
Mounting Size	8mm	Rectifier			
Mounting Finish	Black Bezel	AC current			
Protection	IP40	DC current			
Mount Holder	Recessed	Voltage Tolerance (%)	10%		
Chip Qty	1	Optimum temperature (°C)	-40°C...+85°C		
Indicator colour	Blue	Storage temperature (°C)			
Wavelength (nm)	470	Contact Tab x 2	2.8x0.8mm		