

# RCD / personal protection socket strip (type E) 4-fold with switch

Item-no.: 0220x02042301 (1,5 m cord) | 0220x02042303 (3 m cord)



Robust plastic, grey

Built-in sockets (90° rotated), round

Extra large space in between sockets 64 mm

1,5 m power cord and angle plug (optional with 3 m power cord)

Personal protection through RCD (10 mA)


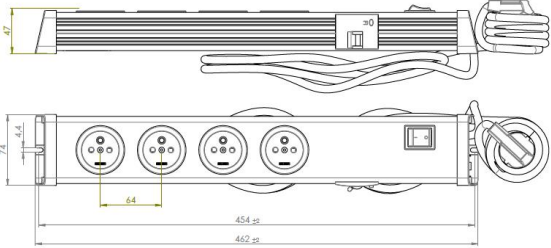
Expanded contact protection by using a shutter

End caps with mounting possibility



## RCD / personal protection socket strip (type E) 4-fold with switch

Technical data

3.600 W Power	230 V ~ (+/- 10%) / 50 Hz Rated voltage	16 A Rated current
Power cord: H05VV-F 3G 1,5 mm <sup>2</sup> Plug: CEE 7/7 plug, angular type EF Sockets: earthing contact type E (French standard) Switch: 2-pole, illuminated Personal Protection: RCD (10 mA) Own Consumption: < 0,5 W Safety class: IP20		
 <p>(similar illustration)</p>		
Item-no. 0220x02042301 (1,5 m cord)    EAN 4012096004967    PU 20 Item-no. 0220x02042303 (3 m cord)    EAN 4012096013266    PU 20		462 x 74 x 47 mm Dimensions (L x W x H) 454 mm Fixing dimension X