

**3/8"****3093 U-3****REVERSIBLE RATCHET 3/8"**

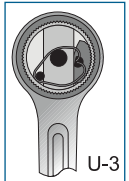
- Acc. to DIN 3122, ISO 3315
- With non-slip metal disc change, fine-toothed and robust
- For hand-operated sockets and accessories with square drive as per DIN 3120 - C 10, ISO 1174, ball locking device
- GEDORE vanadium steel 31CrV3, chrome-plated

**10**
3/8"

Code	No.	□"	■	∠°	↳mm↳	↔	↺↻	📦	£
6237090	3093 U-3	3/8	10	5	200	33.5	244	5	

3093 GU-3**SWIVEL HEAD REVERSIBLE RATCHET 3/8"**

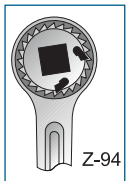
- Swivels through 180°, with joint lock
- With non-slip metal disc change, fine-toothed and robust
- Max. torque 200 N-m
- For hand-operated sockets and accessories with square drive as per DIN 3120 - C 10, ISO 1174, ball locking device
- GEDORE vanadium steel 31CrV3, chrome-plated

**10**
3/8"

Code	No.	□"	■	∠°	↳mm↳	↔	↺↻	📦	£
6237170	3093 GU-3	3/8	10	5	282	33.5	525	5	

3093 Z-94**RATCHET HANDLE WITH COUPLER 3/8"**

- Acc. to DIN 3122, ISO 3315
- With square coupler, medium-fine toothed, extremely rugged
- For hand-operated sockets and accessories with square drive as per DIN 3120 - C 10, ISO 1174, ball locking device
- GEDORE vanadium steel 31CrV3, chrome-plated

**10**
3/8"

Code	No.	□"	■	∠°	↳mm↳	↔	↺↻	📦	£
6237680	3093 Z-94	3/8	10	10	200	18	223	5	

3093 U-10 K**PLASTIC RATCHET 3/8"**

- For fast and easy tightening of bolted connections up to max. 70 N-m
- Very handy and compact, housing and handle form one unit
- Return angle 11.25°
- Made from sturdy compound material with a steel mechanism
- Dimensions: 44 x 145 x 39 mm
- Available in five colours
- European-Patent-No. 1136187

**10**
3/8"

Code	No.	Colour	□"	■	↳mm↳	∠°	↺↻	📦	£
6242090	3093 U-10 K SCHWARZ	signal-black	3/8	10	145	11,25	197	5	
6244970	3093 U-10 K GRÜN	moss-green	3/8	10	145	11,25	197	5	
6248100	3093 U-10 K GRAU	anthracite-grey	3/8	10	145	11,25	197	5	
6248290	3093 U-10 K BLAU	sky-blue	3/8	10	145	11,25	197	5	
1505394	3093 U-10 K SIGNALGRAU	signal-grey	3/8	10	145	11,25	197	1	

3093 U-3 T**RATCHET WITH T-HANDLE 3/8"**

- Two-wing T-handle
- Ergonomic design for comfortable working
- For hand-operated sockets and accessories with square drive as per DIN 3120 - C 10, ISO 1174, ball locking device
- The danger of the tool canting, when carrying out work with extensions, is reduced by the central positioning of the square drive

**10**
3/8"

Code	No.	□"	■	∠°	↳mm↳	↔	📦	£
1973320	3093 U-3 T	3/8	10	5	140	68	1	