




**Part Number :** [982670310](#)

**Product Description :** 1.00mm Pitch Premo-Flex FFC Jumper, Opposite Side Contacts (Type D), 305.00mm Cable Length, Tin (Sn) Plating, 14 Circuits

**Series Number :** 98267

**Status :** Active

**Product Category :** Flat-Flexible Cable (FFC)

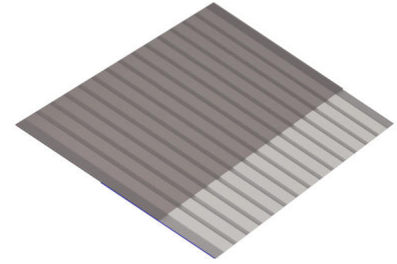

---

## Documents & Resources

### Drawings

[982670310 sd.pdf](#)

[STEP AP242](#)

[SOLIDWORKS](#)

[Creo](#)

### Specifications

[PS-98267-001-001.pdf](#)

---

## Product Environment Compliance

### Compliance

|                    |  |
|--------------------|--|
| GADSL/IMDS         | Not Relevant                                   |
| China RoHS         | Not Reviewed per SJ/T 11365-2006               |
| EU ELV             | Not Relevant                                   |
| Low-Halogen Status | Not Reviewed per IEC 61249-2-21                |
| REACH SVHC         | Not Reviewed per D(2025)4165-DC (25 June 2025) |
| EU RoHS            | Not Reviewed per EU 2015/863                   |

### Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

### Industry Documents

- IPC 1752A Class C

- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

---

## Part Details

### General

|              |   |
|--------------|---|
| Status       | Active  |
| Category     | Flat-Flexible Cable (FFC)   |
| Series       | 98267   |
| Description  | 1.00mm Pitch Premo-Flex FFC Jumper, Opposite Side Contacts (Type D), 305.00mm Cable Length, Tin (Sn) Plating, 14 Circuits |
| Comments     | Contacts on opposite sides, Type D  |
| Product Name | Premo-Flex FFC Jumper   |
| UPC          | 756054773123  |

### Electrical

|                               |        |
|-------------------------------|--------|
| Current - Maximum per Contact | 1.2A   |
| Voltage - Maximum             | 60V AC |

### Physical

|                               |                   |
|-------------------------------|-------------------|
| Cable Length                  | 305.00mm          |
| Circuits (Loaded)             | 14                |
| Contact Layout Type           | D (opposite side) |
| Design Feature                | Extra-Flexible    |
| Material - Plating Mating     | Tin               |
| Net Weight                    | 3.125/g           |
| Packaging Type                | Bag               |
| Pitch - Mating Interface      | 1.00mm            |
| Temperature Range - Operating | -40° to +105°C    |

|                   |                 |
|-------------------|-----------------|
| Termination Style | FFC Connector   |
| Wire/Cable Type   | Flat Flex Cable |
| Wire Size (AWG)   | N/A             |

## Mates With / Use With

### Mates with Part(s)

| Description   | Part Number                      |
|---|----------------------------------|
| Easy-On FFC/FPC Connector, 1.00mm Pitch, Slider Series, Right-Angle, Bottom Contact, 3.00mm Height, 14 Circuits, Tin-Bismuth Plating        | <a href="#"><u>522711479</u></a> |
| Easy-On FFC/FPC Connector, 1.00mm Pitch, Slider Series, Vertical, 5.75mm Height, 14 Circuits, Tin-Bismuth Plating                           | <a href="#"><u>526101471</u></a> |
| Easy-On FFC/FPC Connector, 1.00mm Pitch, Slider Series, Vertical, 5.75mm Height, 14 Circuits, Tin-Bismuth Plating, with Pick-and-Place Tape | <a href="#"><u>526101475</u></a> |
| 1.00mm Pitch Easy-On FFC/FPC Connector, Surface Mount, Vertical, Non-ZIF, Tin (Sn) Plating, 14 Circuits                                     | <a href="#"><u>528081470</u></a> |
| 1.00mm Pitch Easy-On FFC/FPC Connector, Surface Mount, Vertical, Non-ZIF, Tin (Sn) Plating, with Pick-and-Place Polyimide Tape, 14 Circuits | <a href="#"><u>528081471</u></a> |
| Easy-On FFC/FPC Connector, 1.00mm Pitch, Slider Series, Right-Angle, Top Contact, 2.70mm Height, 14 Circuits, Tin-Bismuth Plating           | <a href="#"><u>522071485</u></a> |
| 1.00mm Pitch Easy-On FFC/FPC Connector, Surface Mount, Right-Angle, Non-ZIF, Top Contact Style, 14 Circuits                                 | <a href="#"><u>527931470</u></a> |
| 1.00mm Pitch Easy-On FFC/FPC Connector, Vertical, Surface Mount   | <a href="#"><u>528061410</u></a> |

|  |                  |
|--|------------------|
| Compatible, Non-ZIF, Kinked PC Tails, 14 Circuits  |                  |
| 1.00mm Pitch Easy-On FFC/FPC Connector, Right-Angle, Non-ZIF, Top Contact Style Receptacle, 14 Circuits        | <u>528071410</u> |
| 1.00mm Pitch Easy-On FFC/FPC Connector, Surface Mount, Right-Angle, Non-ZIF, Bottom Contact Style, 14 Circuits | <u>528521470</u> |