



Data sheet

ENGLISH

Stock No. 122-8900(with UK plug) & 122-8902 (with EU plug)

RS PRO 60W PROTABLE LED WORK LIGHT




Specifications:

Working Power	60W
LED Chip/ Brand	COB
Lumen output	4500lm
CCT	6000K
CRI	>80
Beam Angle	120°
Power supply	100~240V 50/60Hz
Cable Type	H05RN-F, 3Gx1,0mm ²
Cable Length	3 meter
Plug Type	UK PLUG or EU plug
Connector	Fixed connector

Features:

1. Dual 2x30W Ultra Bright COB LEDs
2. Power Button with 2 settings: High/Saving mode

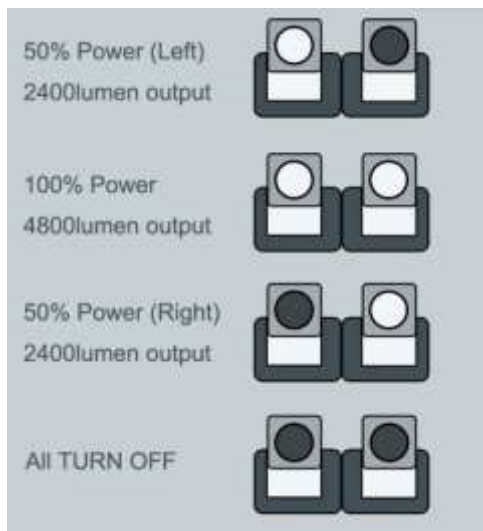

3. IP44 Weather Resistant and can be used different application



4. IK08 Impact Resistant Hard Case
5. Rotation angle could be 350 degree



6. Cable Protected M16 connector&IP65 Level Switch



Product size:



Optional accessory: Metal stand (RS article 1228901)

