

Product information

82 01 200 SB

KNIPEX TwinGrip

Front and side gripping plier



- Gripping, tightening and loosening screws with worn heads and threads
- Unique combination: Front grip and side grip function, box joint, push button adjustment
- High-grip front jaw with robust teeth and high gear ratio at the tip of the mouth
- The all-rounder for all common tasks
- Large front and side gripping capacity for diameters and widths across flats 4 - 22 mm
- Very slim pliers let you work even in confined installation spaces with a narrow turning zone for fast results
- Pinch stop reduces the risk of crushed fingers
- Reliable, frontal gripping of flat workpieces up to 8 mm thanks to three-point system
- Three-way adjustable slip joint with push button adjustment for precise alteration of gripping capacity
- Durable and resilient thanks to robust box joint



General

Article No.	82 01 200 SB
EAN	4003773087571
pliers	grey atramentized
head	polished
handles	covered with non-slip plastic
Weight	236 g
Dimensions	200 x 85 x 19 mm
REACH compliant	does not contain SVHC
RoHS compliant	not applicable

Technical details



adjustment positions	5
Capacities for pipes (diameter)	Ø 5/32 – 7/8 Inch
Capacities for pipes (diameter)	Ø 4 – 22 mm
Capacities for nuts	4 – 22 mm
Capacities for nuts	5/32 – 7/8 Inch

technical change and errors excepted



The box-joint is robust and flexible, so that the pliers can hold workpieces between 4 and 22 mm in place.



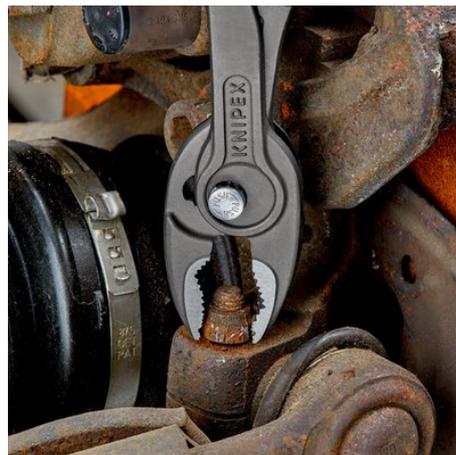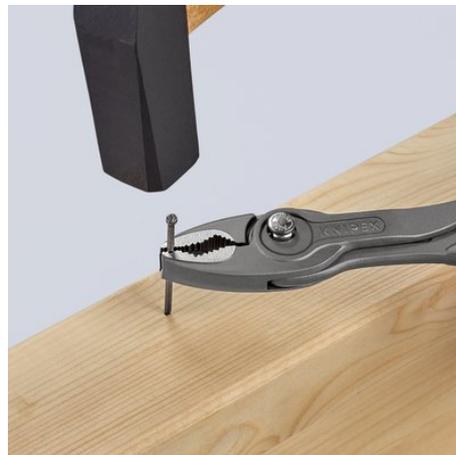



Comfortable and reliable: The push-button adjusts the gripping capacity in five steps directly on the workpiece and then locks securely – no accidental loss of adjustment!



Optimised jaw geometry: 2-zone gripping jaw with opposing alignment of teeth – for maximum grip when loosening and tightening.