


## OPEN HOSE REELS FOR COMPRESSED AIR / STEEL

DMO series - Medium - Rubber hose



| Part number | Length (m) | Flow rate (l/min) | Temperature min/<br>max (°C) | Max. operating<br>pressure (bar) | Net weight (Kg) | Female thread | Profile  |
|-------------|------------|-------------------|------------------------------|----------------------------------|-----------------|---------------|----------|
| DMO 1020ES  | 20.00      | 660.00            | -15.00 / 40.00               | 12.00                            | 18              | G3/8          | EUROPEAN |
| DMO 1315ES  | 15.00      | 1400.00           | -15.00 / 40.00               | 12.00                            | 18              | G3/8          | EUROPEAN |

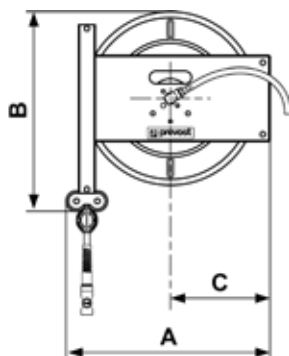

| Part number | Dim. A (mm) | Dim. B (mm) | Dim. C (mm) | Ø int/ext (mm) |
|-------------|-------------|-------------|-------------|----------------|
| DMO 1020ES  | 485.00      | 475.00      | 237.00      | 10.00 / 17.00  |
| DMO 1315ES  | 485.00      | 475.00      | 237.00      | 13.00 / 20.00  |