




**TAH2628G**

**ERGO™ Combination Pliers with  
Safety Ring**



## PRODUCT DETAILS

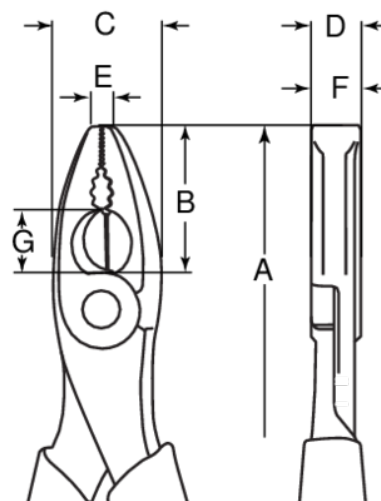


- Combination pliers developed according to the scientific ERGO™ process
- ERGO™ handles with two-component combination, thermoplastic surface on tough polypropylene to give a superior grip
- Cutting edge specially designed to cut harder material such as piano wire
- Equipped with a return spring featuring an on/off function
- Material: High performance alloy steel
- Finish: Black finish, anti-corrosion treated
- ISO 5746
- Suitable for working at height
- Permanent stainless steel ring attached directly to the body of the plier maintains user ergonomics and full functionality
- Colour plate with maximum weight for a right matching with the lanyard
- Safety ring is attached to the metallic part to avoid losing handle
- According to DROPS best practices



**Follow the Fish!**



## PRODUCT ATTRIBUTES

| Product             | <b>A</b> | <b>B</b> | <b>C</b> | <b>D</b> | <b>E</b> | <b>F</b> | <b>G</b> |  |  |  |
|---------------------|----------|----------|----------|----------|----------|----------|----------|---|---|---|
| <b>TAH2628G-160</b> | 170 mm   | 33 mm    | 23 mm    | 10 mm    | 4 mm     | 10 mm    | 12 mm    | 2.0 mm  | 1.8 mm  | 180 g   |
| <b>TAH2628G-180</b> | 190 mm   | 35 mm    | 24 mm    | 11 mm    | 4 mm     | 11.0 mm  | 14 mm    | 2.5 mm  | 2.0 mm  | 230 g   |
| <b>TAH2628G-200</b> | 200 mm   | 39 mm    | 27,9 mm  | 12 mm    | 4 mm     | 12.0 mm  | 16 mm    | 3.0 mm  | 2.5 mm  | 310 g   |

**Follow the Fish!**

