
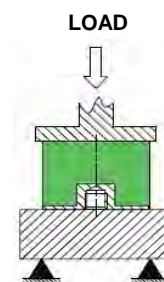


Bobbin Mount End Stop - Type DE (Female)

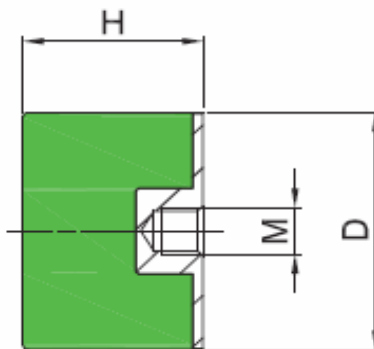

The Type VP Bobbin Mount End Stops are designed to be used on a wide range of applications to prevent shocks and over-loading thanks to their progressive absorption.

They are manufactured from Natural Rubber in a variety of hardnesses to suit the application, and have a zinc plated steel end section with either welded or cold formed threads.

This range comes with a Female thread on one end that is captive to avoid compromise to the integrity or functionality of the Rubber section.

RS Ref:	Fibet Ref:	D	H	M	IRHD	Stiffness (DaN/mm)	Max. Static Deflection (mm)	Maximum Stiffness (DaN)
257-8729	1610DE04-45	16	10	M4	45	8.1	2.0	16.2
777-3247	1615DE05-45	16	15	M5	45	4.3	3.0	12.9
257-8735	1620DE05-45	16	20	M5	45	4.3	4.0	17.2
257-8757	2015DE06-60	20	15	M6	60	13.3	3.0	39.9
777-3250	2025DE06-60	20	25	M6	60	5.5	5.0	27.5
257-8763	3017DE08-60	30	17	M8	60	29.0	3.4	98.6
777-3241	3022DE08-45	30	22	M8	45	9.8	4.4	43.1
720-3366	5021DE10-60	50	21	M10	60	100.0	4.2	420.0
720-3360	7540DE12-60	75	40	M12	60	93.3	8.0	746.4