


Product data sheet

Specifications

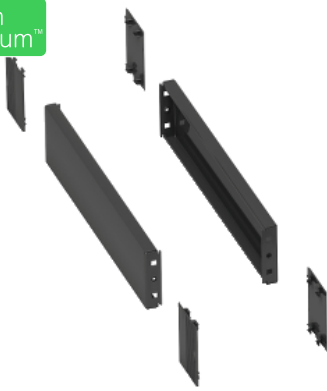

2 side panels for plinth.
500x100mm. Folded sheet steel

NSYSPS5100SD

Main

Range	Spacial
Accessory / separate part category	Enclosure accessory
Product or component type	Plinth side panel
Anwendung	Multi-purpose
Nennmaße des Gehäuses	-
Device composition	fixing elements 4 corner cover 2 side panel
Range compatibility	Spacial SD
Mounting support	Fixed to the corners

Complementary

Fixing mode	By 2 screws
Colour	Grey (RAL 7022)
Surface finish	Epoxy-polyester powder
Height	100 mm
Width	500 mm

Environment

IP degree of protection	IP30 (complete plinth)
IK degree of protection	IK10 (resistance to external mechanical impacts)

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Weight	1.2 kg
Package 1 Height	5.8 cm
Package 1 width	10.8 cm
Package 1 Length	31.3 cm

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS declaration Product out of China RoHS scope. Substance declaration for your information
Environmental Disclosure	Product Environmental Profile

Contractual warranty

Warranty	18 months
----------	-----------