


## Specification sheet : SP-DSR-187

Firm : Distrelec Schweiz AG  
Address : Grabenstrasse 6  
Zip / City : 8606 NÄNIKON  
Customercode : 13996215 / DSR

TBS partnumber : **SP-DSR-187**  
Date : 17-6-2021  
Your partnumber : 302-22-145

## Coiled cable dimensions

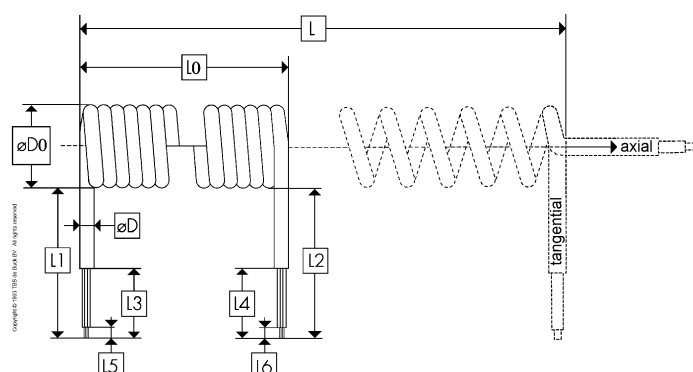

|      |                    |
|------|--------------------|
| L=   | 1200 mm.           |
| L0=  | 300 mm.            |
| ØD=  | 5,5 mm.            |
| ØD0= | 20,0 mm.           |
| L1=  | 200 mm. tangential |
| L2=  | 200 mm. tangential |
| L3=  | mm.                |
| L4=  | mm.                |
| L5=  | mm.                |
| L6=  | mm.                |

Weight: ± 0,13 kg / pc

## Cable specification

Cable type : LiF12YD11Y 6x0,25 mm<sup>2</sup> TB50 FLEX  
Stranding : 32x0,10 mm bare copper wires  
Conductor insulation : TPE-E  
Conductor colours : according to DIN 47100  
Shielding : by a lap of 0,10 mm tinned copper wires  
Overall sheath : PUR  
Colour : black (semi-glossy)  
Temperature range : -25 °C to +70 °C



Photographs are for illustrative purposes only

### Tolerances ± 10% (dimensions and quantities)

**Attention:** Coiled cables, power cords and (cable)assemblies are customized products, specifically manufactured and supplied upon order. Therefore these products cannot be returned or exchanged in any way. Offer is non-committal, fixed price for up to 6 weeks, subjected to prior sale, subjected to technical changes, especially changes in measurement and construction. All our offers, orders granted to us and (project) contracts/agreements with us are subjected to the METAALUNIE TERMS AND CONDITIONS only. These terms and conditions have been filed at the Registry of the Rotterdam District Court.

TBS de Buck B.V.  
De Slof 2 5107 RJ Dongen  
The Netherlands  
V.A.T.-nr.: NL 8059.10.888.B01

HR Eindhoven nr.: 18048791  
Rabobank Tilburg nr.: 0304.1314.07  
IBAN code : NL39 RABO 0304 1314 07  
BIC code : RABONL2U

Phone : +31 (0) 162 523 436  
E-mail : sales@the-best-solution.com  
Internet : www.the-best-solution.com