


BOX JOINT AND GROOVE JOINT PLIERS

EGA Master manufactures a wide range of groove joint and box joint pliers, among which the most remarkable are **AUTO GRIP** pliers. They are **extensible multi-position pliers** with a fast adjusting system, designed for most demanding professionals.



Gold Medal
International Inventors
Competition,
Paris 2007

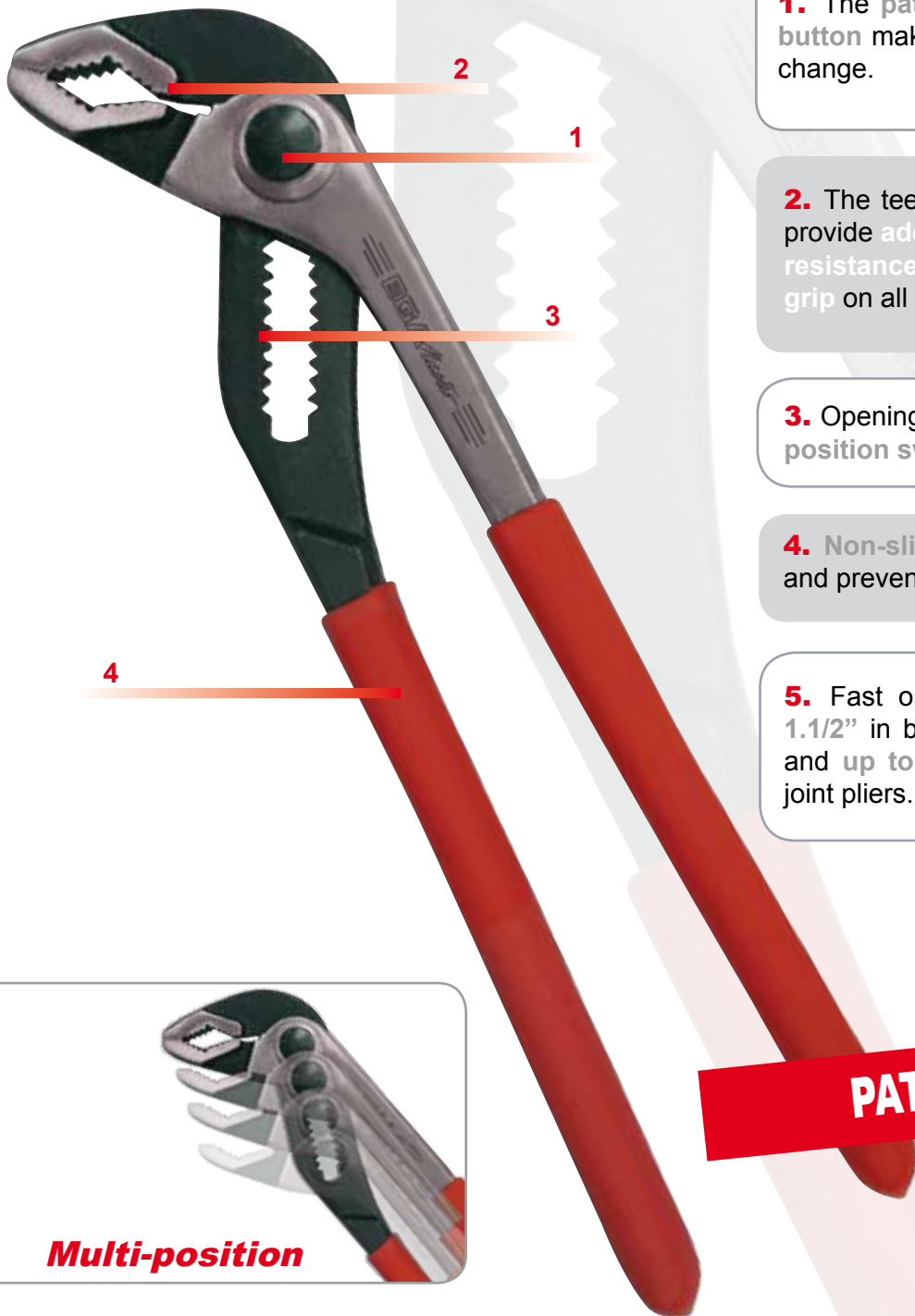

1. The patented fast adjusting button makes easier the position change.



2. The teeth, heat treated, provide adequate wear resistance and a firm grip on all surfaces.



3. Opening selection system avoids involuntary position switching.

4. Non-slip plastic handles ensure a good grip and prevent unwanted slipping.

5. Fast opening up to 1.1/2" in box joint pliers and up to 2" in groove joint pliers.



PATENTED

Multi-position




AUTO GRIP BOX JOINT PLIERS



DIN 8976

Up to 16 positions!
Fast opening up to 1.1/2"!

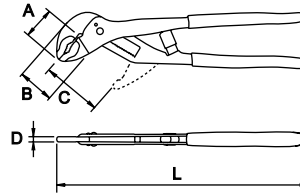

COD	L	A	B	C	D	Weight	Red	Black
62706	7"	24	30	47	6	200		
62707	10"	30	39	59	7,5	350	6	1
62708	12"	36	46	71	8	550		

Cr-V

TECHNICAL SPECIFICATIONS


MATERIAL	Chrome-Vanadium (Cr-V)	
HARDNESS	General	43-48 HRc
	Teeth	42-50 HRc
	Pin	28-50 HRc
FINISH	Black	
	Handles	Anti-slip RAL 2002 red colour

PATENTED



DIN 8976

Up to 16 positions!
Fast opening up to 1.1/2"!

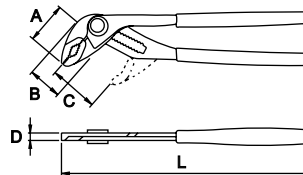

COD	L	A	B	C	D	Weight	Red	Black
62328	8"	28	30	37	9	300		
62329	9,5"	38	35	43	11	400	6	5

Cr-V

TECHNICAL SPECIFICATIONS


MATERIAL	Chrome-Vanadium (Cr-V)	
HARDNESS	General	44-50 HRc
	Jaws	42-50 HRc
FINISH	Black	
	Handles	Anti-slip RAL 2002 red colour

BOX JOINT

TITACROM® B MAT



DIN 8976

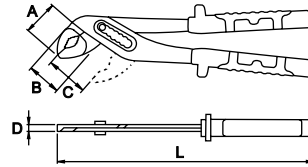

COD	L	A	B	C	D	Weight	Box	Carton
62297	10"	32	36	34	7,0	400	6	6
62298	12"	43	46	46	8,0	610	6	6

TECHNICAL SPECIFICATIONS


MATERIAL	Chrome-Vanadium (Cr-V)	
	Handles	Bimaterial
HARDNESS	General	40-48 HRc
	Teeth	42-50 HRc
	Pin	28-50 HRc
FINISH	Titacrom	

BOX JOINT

TITACROM®



DIN 8976

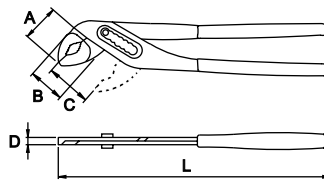

COD	L	A	B	C	D	Weight	Box	Carton
62294	10"	32	36	34	7,0	400	6	6
62295	12"	43	46	46	8,0	610	6	6

TECHNICAL SPECIFICATIONS


MATERIAL	Chrome-Vanadium (Cr-V)	
	General	43-48 HRc
HARDNESS	Teeth	42-50 HRc
	Pin	28-54 HRc
	FINISH	Titacrom
	Handles	Anti-slip RAL 2002 red colour

BOX JOINT

TITACROM®



DIN 8976

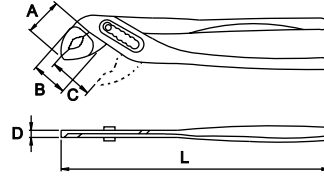

COD	L	A	B	C	D			
62291	10"	32	36	34	7,0	400	12	5
62292	12"	43	46	46	8,0	600	6	


TECHNICAL SPECIFICATIONS

MATERIAL	Chrome-Vanadium (Cr-V)	
HARDNESS	General	40-48 HRc
	Teeth	42-50 HRc
	Pin	28-50 HRc
FINISH	Titacrom	

BOX JOINT



DIN 8976

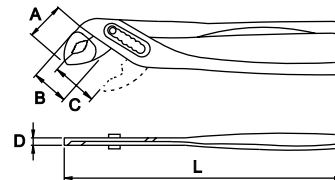

COD	L	A	B	C	D			
62133	7"	28	28	25	7,0	165	12	6
62135	10"	32	36	34		400		
62134	12"	43	46	46	8,0	600	6	


TECHNICAL SPECIFICATIONS

MATERIAL	Chrome-Vanadium (Cr-V)	
HARDNESS	General	43-48 HRc
	Teeth	42-50 HRc
	Pin	28-54 HRc
FINISH	Painted in epoxy powder red color ral-2002 semi-texturized	

BOX JOINT



DIN 8976

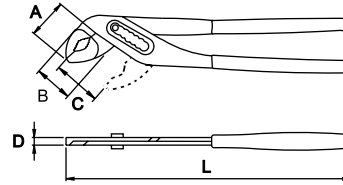

COD	L	A	B	C	D			
62127	7"	28	28	25	7,0	165	12	6
62128	10"	32	36	34		350		
62129	12"	43	46	46	8,0	500	6	


TECHNICAL SPECIFICATIONS

MATERIAL	Chrome-Vanadium (Cr-V)	
HARDNESS	General	43-48 HRc
	Teeth	42-50 HRc
	Pin	28-50 HRc
FINISH	Painted in epoxy powder red color ral-2002 semi-texturized	
	Handles	Black soft foam grip

NEAT TIPS



DIN 8976

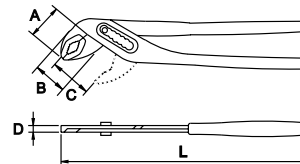

COD	L	A	B	C	D			
62793	7"	27	27	25	7,0	150	12	6
62794	10"	32	33	32		300		
62795	12"	40	35	43	9,0	400	6	

TECHNICAL SPECIFICATIONS


MATERIAL	Chrome-Vanadium (Cr-V)	
HARDNESS	General	43-48 HRc
	Teeth	42-55 HRc
	Pin	28-54 HRc
FINISH	Painted in epoxy powder red color ral-2002 semi-texturized	

AUTO GRIP GROOVE JOINT TITACROM®



DIN 8976

**Up to 18 positions
Fast opening up to 2"!**

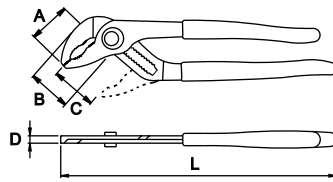

COD	L	A	B	C	D			
62411	8"	30	37	31	10	300		
62412	10"	37	41	47	12	450	6	6
62413	12"	48	48	49	13	650		

Cr-V

TITACROM® Is a special surface treatment, rust-proof and anti-chipping off. It is non-reflecting and with very attractive finishing.


TECHNICAL SPECIFICATIONS

MATERIAL	Special Steel	
HARDNESS	General	44-50 HRc
FINISH	TITACROM®	
	Handles	Anti-slip RAL 2002 red colour

GROOVE JOINT TITACROM® B.M.A.T



DIN 8976

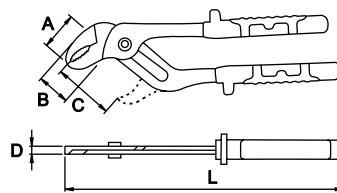

COD	L	A	B	C	D			
62445	8"	30	36	30	9,0	300		
62446	10"	34	40	36	10	460	5	5
62447	12"	43	48	48	11	700		

TECHNICAL SPECIFICATIONS


MATERIAL	Special Steel	
HARDNESS	Handles	Bimaterial
	General	45-50 HRc
FINISH	Screw	28-50 HRc
	TITACROM®	

GROOVE JOINT

TITACROM®



DIN 8976

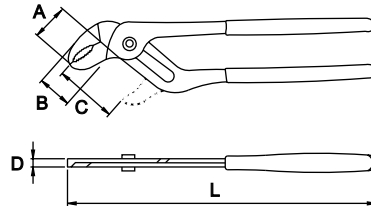

COD	L	A	B	C	D	Weight	Material	Accessories
62105	8"	30	36	30	9,0	240	6	6
62106	10"	34	40	36	10	390		-
62107	12"	43	48	48	11	600	6	6
62108	16"	70	60	85	12	1300		-

TECHNICAL SPECIFICATIONS

MATERIAL	Special Steel	
HARDNESS	General	45-50 HRc
	Screw	28-50 HRc
FINISH	TITACROM®	
	Handles	Anti-slip RAL 2002 red colour