



SETRON, cylindrical fuse link, 22x58 mm, 40 A, gG, Un AC: 690 V

Figure similar

Model			
product brand name		SETRON	
product designation		Cylindrical fuse link	
General technical data			
operating class of the fuse link		gG	
type of voltage of the operating voltage		AC	
supply voltage at DC		250 V	
Dissipation			
power loss [W]		4.5 W	
power loss [W] for rated value of the current at AC in hot operating state per pole		5 W	
Main circuit			
operational current rated value		40 A	
Product details			
product component striker		No	
Mechanical Design			
mounting position		Any, preferably vertical	
net weight		51 g	
Approvals Certificates			
General Product Approval		other	Environment



[Miscellaneous](#)

[Confirmation](#)

[Environmental Confirmations](#)

Further information

Information on the packaging

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3NW6217-1>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/3NW6217-1>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3NW6217-1

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

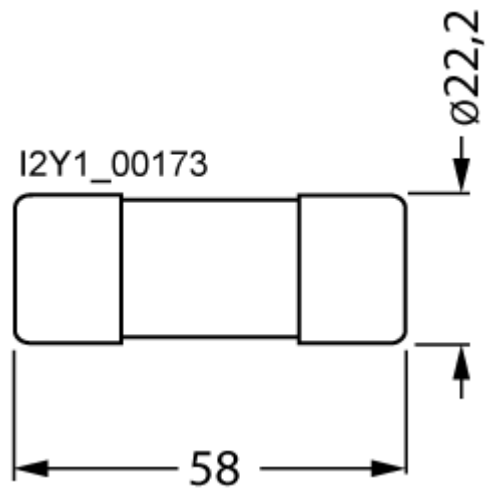

last modified:

4/11/2025 

