

Portable Digital Microscope

Product Image



Model: AD413T-I2V-A

**Dino-Lite Pro AD413T-I2V-A
(USB) 10x ~ 50x, 200x**

UV + IR

"AMITA" RACK INCLUDED !!!!

Resolution: 1.3M pixel

Adjustable Magnification: 10x ~ 50x, 200x (Continuous magnification without switch lenses)

Illumination: 4 UV Led (400nm) + 4 IR Led (850nm) ON/OFF controlled by software

Frame rate: up to 30fps, 15fps at 1,3M

Interface: USB 2.0 (PC)

Software: DinoCapture 2.0 included

Compatibility: Windows 2000/XP, Vista, 7 and MAC X computers (10.4 or further release)

Sensor: Color CMOS

Weight: ~155g

Dimensions: 10cm (H) x 3,2cm (D)

Aluminum Alloy Housing

Functions:

Capture a photograph, video or time-lapsed video with a click
Microtouch snapshot (only for Windows system)
Accurate measurement & calibration capability



Accessories included

FC-OC1 Open Cover - FC-T-CC1 Cover closed



Science / Engineering work / Study / Detailed repair / Assembly & quality control / Electronic industry / Mechanical industry / Hobbies & collecting (coin, stamp, watch, jewelry, etc) On line chatting / Antiques / Enforcement

Photos

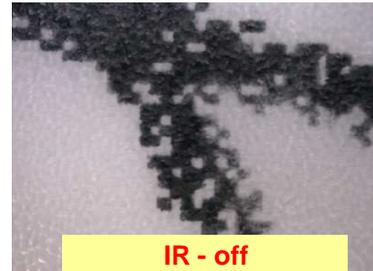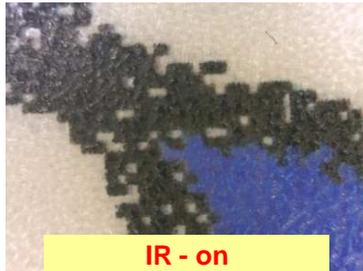

Manufactured by:
ANMO
Electronics Corporation.

Imported by:
italeco



For more details visit the
website www.dinolite.it