



Visit the website for your country to get more information and discover our products.

India ▾

[Proceed](#)

HellermannTyton

09/07/2026

Cable tie mount for edge, T=12.0 - 14.0mm, black, 96pcs.

Art.-No. 156-03629 | HDEC12-14-PA6GF30/C75S-BK | [Copy item description](#)



- PFAS-free metal clamp for environmentally conscious applications
- Supports up to three cable ties for secure multi-cable bundling
- Compatible with five panel thicknesses: 6–8 mm, 8–10 mm, 10–12 mm, 12–14 mm, and 14–16 mm
- Heavy-duty design ensures reliable performance in demanding environments



More products in this product group:





Visit the website for your country to get more information and discover our products.

[Proceed](#)

HellermannTyton

09/07/2026

Application	The new Heavy Duty EdgeClips are specifically designed for high-load applications in challenging environments such as truck manufacturing, wind energy systems, and industrial installations including steel construction and structural beams. Installation can be carried out using either a dead blow hammer or, for the HDEC-Pre versions, water pump or channel lock pliers, offering flexibility on-site. The design allows for parallel routing of up to three cables and lines, supporting organized and efficient cable management even under demanding conditions.
Colour	Black (BK)
Fixation Method	Edge Clip
Material	Polyamide 6, glass-fibre reinforced (PA6GF30), Steel C75S (C75S)
PART DESCRIPTION	HDEC12-14-PA6GF30/C75S-BK
Package Content	96 pcs.
Package Content packed in	box
Product Family	HDEC-Series for heavy duty applications
Product Group	Heavy Duty EdgeClip
Short Description	PFAS-free Heavy Duty EdgeClip: holds up to 3 cable bundles, easy edge mounting (10–12 mm) with dead blow hammer.
Type	HDEC12-14
Variant	Edge Clip
Weight/Unit	0.022985 kg

 Visit the website for your country to get more information and discover our products.

[Proceed](#)



09/07/2026

Length (L)	12.0 mm
Panel Thickness	12.0 - 14.0 mm
Width (W)	35.0 mm
for Panel Thickness	12 - 14 mm
s min - max	

Specifications

ELV compliant (Article 4 - 2)	Yes
Halogen-free	Yes
Hazardous Goods	No
Operating Temperature	-40 °C to +120 °C, (+150 °C, 5000h; +160 °C, 3000h; 180 °C, 100h)
PFAS-free	Yes
ROHS compliant	Yes
Reusable (Yes/No)	No
Specifications	HF✓ RoHS✓





Visit the website for your country to get more information and discover our products.

[Proceed](#)

HellermannTyton

09/07/2026

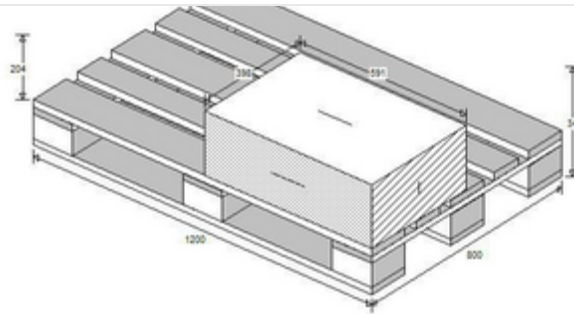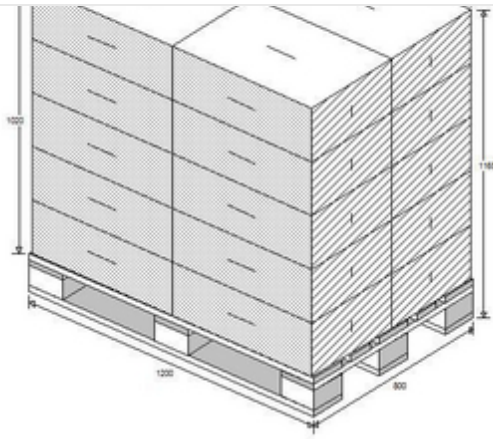

Country of Origin	PL
Customs Number	39269097
GTIN-13 / EAN	4031026759883
Packaging 1 - Height (m)	0.17 m
Packaging 1 - Length (m)	0.288 m
Packaging 1 - Qty	96
Packaging 1 - Type	box
Packaging 1 - Volume (m ³)	0.00871488 m ³
Packaging 1 - Weight (kg)	2.326352 kg
Packaging 1 - Width (m)	0.178 m
Packaging 3 - Height (m)	0.204 m
Packaging 3 - Length (m)	0.591 m
Packaging 3 - Qty	384
Packaging 3 - Type	box



Visit the website for your country to get more information and discover our products.

Proceed

HellermannTyton

09/07/2026

Packaging 3 - Width 0.598 m
h (m)

Packaging 4 - Height 1.204 m
ht (m)

Packaging 4 - Length 1.2 m
th (m)

Packaging 4 - Qty 7680

Packaging 4 - Type pallet

Packaging 4 - Volume 1.156 m³
me (m³)

Packaging 4 - Weight 227.445 kg
ght (kg)

Packaging 4 - Width 0.8 m
h (m)

More Information

ETIM 7.0 Key EC000449

ETIM 8.0 Key EC000449

ETIM 9.0 Key EC000449

UNSPSC Key 39121717

HellermannTyton



International

Imprint

Policy and Values

Sitemap



Visit the website for your country to get more information
and discover our products.

[Proceed](#)

HellermannTyton

09/07/2026

[Contact](#)

[Terms of Service](#)

[Guidelines and Commitments](#)

[Social Media](#)

© HellermannTyton 2026 (v4.311.8) | [Update: 27/06/2026](#) | [Privacy Settings](#)
