


Professionally approved products.

Compression Springs

Steel Compression Spring

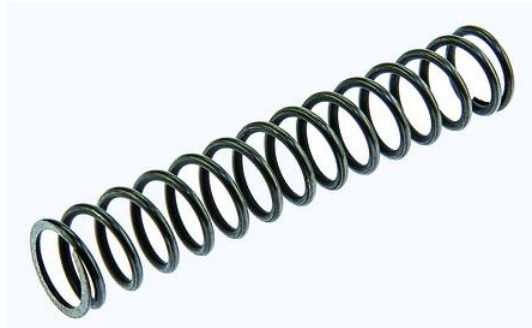

[RS Stock No. 121-157](#)

Features:

Ends : Closed
Material : Steel Alloy

Specification:

RS Stock No.	Free Length	Outside Diameter	Spring Rate	Minimum Working Length
121157	29.5 mm	11.25 mm	4.51N/mm	10.8 mm
121179	41.5 mm	13.75 mm	2.31N/mm	11.6 mm
121185	94 mm	17.25 mm	0.72N/mm	18.5 mm
121191	45 mm	9.6 mm	10.4N/mm	24.8 mm
121220	53.5 mm	14.1 mm	4.04N/mm	20.1 mm
121242	110 mm	21.6 mm	0.99N/mm	25.5 mm
121270	98 mm	18 mm	3.19N/mm	35.9 mm
121286	135 mm	22 mm	1.63N/mm	38.8 mm
121292	135 mm	27 mm	1.23N/mm	31 mm
121315	48.9 mm	15 mm	11.96N/mm	27.4 mm
751360	15.7 mm	2.75 mm	0.22N/mm	5 mm
751455	31 mm	4.5 mm	0.54N/mm	14 mm
751483	20 mm	4.63 mm	2N/mm	11.3 mm

