

 

proximity sensor SMT0-8E-PS-S-LED-24

Part number: 171178

FESTO

Electric, contactless, PNP, for drives with T-slot, without mounting kit, with M8 plug.

Separate mounting component SMB-8E required (part no. 178230)

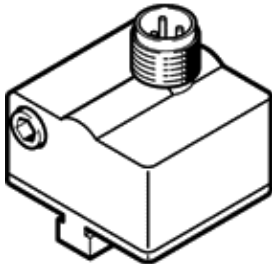

Data sheet

Feature	Value
Design	for T-slot
Authorisation	RCM Mark
CE mark (see declaration of conformity)	to EU directive for EMC
Materials note	Free of copper and PTFE Conforms to RoHS
Measuring principle	Magnetoresistive
Ambient temperature	-20 ... 60 °C
Switch output	PNP
Switching element function	Normally open contact
Reproducibility of switching value	+/- 0,1 mm
Switch-on time	<= 1.3 ms
Switch-off time	<= 1.4 ms
Max. output current	100 mA
Max. contact rating DC	2.8 W
Voltage drop	<= 1.8 V
Residual current	<= 0.01 mA
Short circuit strength	Yes
Overload withstand capability	Available
Operating voltage range DC	10 ... 30 V
Polarity protected	for all electrical connections
Electrical connection 1, connection type	Plug
Electrical connection 1, connection technology	M8x1 A-coded to EN 61076-2-104
Electrical connection 1, number of pins/wires	3
Connector exit direction	Lateral
Max.tightening torque plug	0.3 Nm
Mounting type	Clamped in T-slot Insertable in slot from above with accessories
Tightening torque	1 Nm
Product weight	12 g
Material housing	Brass TPE-U(PU) Nickel plated
Operating status display	Yellow LED
Protection class	IP65 IP67