

# Universal socket strip 3-fold (type E) without power cord with switch

Item-No.: 0201x02032300



Robust plastic, grey

Built-in sockets (90° rotated), round

Extra large space in between sockets 64 mm


Expanded contact protection by using a shutter

End caps with mounting possibility

Without power cord


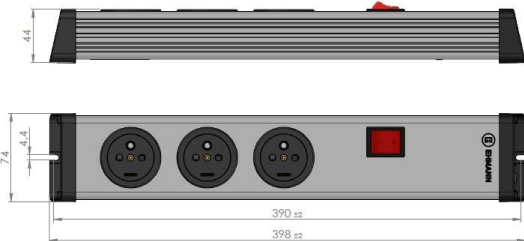
Simple screwed connection

Spacious connection chamber, cable entry (Ø 10 mm)

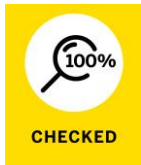

## Universal socket strip 3-fold (type E) without power cord with switch

Technical data

3.600 W Power	230 V ~ (+/- 10%) / 50 Hz Rated voltage	16 A Rated current
Power Cord: without power cord Connecting terminals: up to 2,5 mm <sup>2</sup> per pole Sockets: earthing contact Type E (French standard) Switch: 2-pole, illuminated (red) Consumption per switch: < 0,5 W Safety class: IP20		
 <p>(similar illustration)</p>		
Item-No. 0201x02032300	EAN 4012096013259	PU 10  398 x 74 x 44 mm Dimensions (L x W x H)  390 mm Fixing Dimension