


## FEATURES

- **Non-Releasable Design:** Ensures a secure and permanent fastening solution.
- **Nylon Material:** Provides durability and resistance to wear and tear.
- **UL 94 V-2 Fire Behaviour:** Offers a level of flame retardancy for added safety.
- **Tensile Strength of 18 kg:** Supports robust applications requiring strong hold.
- **Maximum Operating Temperature of 150°C:** Suitable for high-temperature environments.
- **Length of 150 mm:** Ideal for bundling medium-sized cable groups.
- **Width of 3.6 mm:** Balances flexibility and strength for versatile use.

## RS PRO 150mm Nylon Cable Tie, Non-Releasable

RS Stock No: 656-083

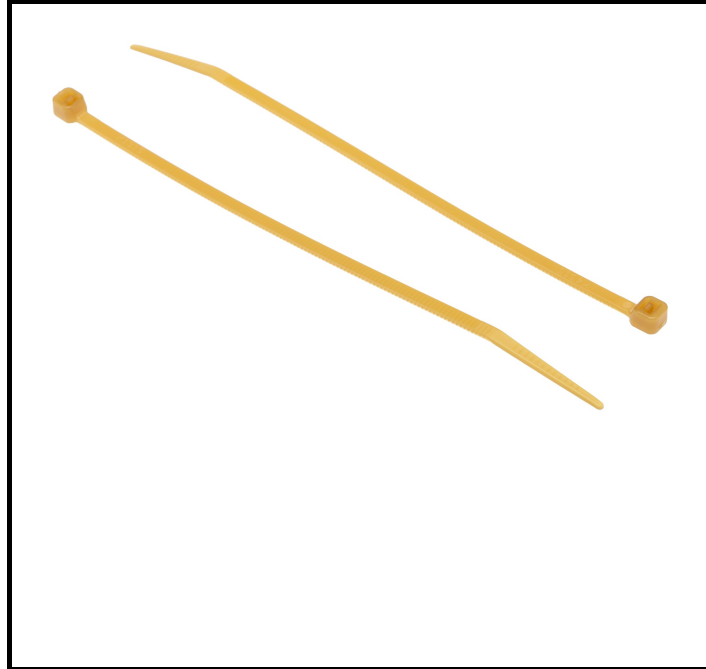

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

### Product Description

RS PRO offers a reliable solution for securing and organising cables with this 150mm nylon cable tie. Designed for non-releasable applications, it provides a strong and durable fastening option for various industrial and commercial uses. The cable tie's light brown colour allows for easy identification and integration into different environments.

### General Specifications

Colour	Light Brown
Product Type	Cable Tie
Sub Type	Non-Releasable
Tensile Strength	18 kg

### Protection Category

Fire Behaviour	UL 94 V-2
UV Resistant	No

### Mechanical Specifications

Length	150 mm
Material	Nylon
Maximum Bundle Diameter	36 mm
Width	3.6 mm

### Operation Environment Specifications

Maximum Operating Temperature	150 °C
-------------------------------	--------

### Approvals

Standards/Approvals	RoHS, UL94V-2
---------------------	---------------

