


Data Specification Sheet

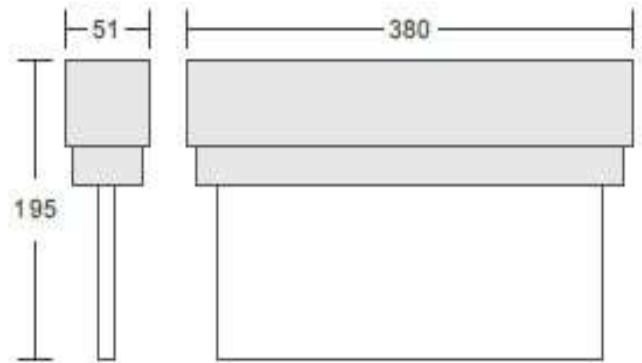

EMEXIT 4 Watt Double Sided LED Emergency Exit Sign

ML Accessories Code	EMEXIT
Description	LED Emergency Double Sided Exit Sign 3 Hour Maintained Arrow Down
Optional Extra Legends	EMEXITL2 – Running Man + Arrow Up EMEXITLR – Running Man + Arrow Right/Left
Overall dimensions (mm) Height – Width - Depth	(H)195mm (W)380mm (D)51mm
Product Weight	1.09kg
Voltage (V)	220-230V 50-60Hz
Lamp Type	16 x SMD 3528 Non replaceable LED
Lumen Output	120Lm
Charge Time (Initial)	24 hours
Discharge Duration	3 Hours
Class	Class II. Must not be Earthed
IP	IP20
Circuit Power	5 watts
Temperature Range	-10 to +30°C
Battery type	Ni-Cd 4.8V 600mAh (4xcell)
Origin of Manufacture	China
Main materials:	
• Chassis (gear tray)	Self-Extinguishing Polycarbonate
• Body	Self-Extinguishing Polycarbonate
• Diffuser	Self-extinguishing Polycarbonate
Method of fix	Direct fixing – Screws provided Ceiling or Wall Mounting
Instruction Sheet	Yes
Electrical Connections	Screw terminals
Running Gear	Electronic
F mark	Yes
CE mark	Yes
Quality Assurance System	Yes ISO 9001 QMS
Batch coding details on product	Yes
Certificate of Conformity (Held on File)	Yes
Warranty	2 year
Manufactured in accordance to:	EN55015. EN61547. EN61000-3-2. EN61347-2-7. EN61347-2-3 BSEN60598

ML Accessories Ltd. reserves the right to withdraw, improve or modify any design without prior notification.

ML Accessories Ltd. cannot be held responsible for the incorrect application of any product.