

MINILYNX 20W E27 BL368 TC

Item No: 0025715

SYLVANIA

SpeciaLITE®




UV-A blacklight lamp with a radiation at 368nm which is widely accepted as the most important frequency for the attraction of insects.

Technical Assets

Dimensions (mm)

E27

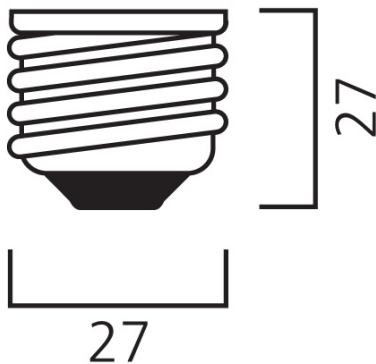

Photometrics

MINILYNX 20W E27 BL368 TC

Item No: 0025715

SYLVANIA

General data

Product name	MINILYNX 20W E27 BL368 TC
Technology	Fluorescent
Lamp shape	U shape
Cap/Base	2G11
Lamp finish	Frosted/Coated
Fixture rating	Enclosed
General application	SPG
ETIM Class	EC002962
Warranty	2 years

Optical data

Light colour	BL368 Blacklight
Photobiological Risk Group	RG0

Electrical data

Supply current (A)	0.1
Primary Supply/Product voltage - min (V)	220
Primary Supply/Product voltage - max (V)	240
Dimmable	No
Inrush Current (A)	15
Inrush Duration (µs)	200
Nominal Frequency (Hz)	50/60Hz

Physical data

Nominal Product Height (mm)	168
Nominal Product Diameter (mm)	54
Weight (kg)	0.102

Packaging

Product EAN number	5410288257150
Packaging single length / height (cm)	5.2
Packaging single width (cm)	5.2
Packaging single depth (cm)	17.4
DUN14 (inner)	15410288257157
Units per inner package	10
Packaging inner length / height (cm)	27.5
Packaging inner width (cm)	11.5
Packaging inner depth (cm)	19.5
DUN14 (outer)	25410288257154
Units per outer package	50
Packaging outer length / height (cm)	63.0
Packaging outer width (cm)	29.5
Packaging outer depth (cm)	22.5

Safety data

Breakage cleaning instructions	Applicable
Special purpose lamp	Yes
Intended purpose	Flykilling - Insect attraction
Suitable for household illumination	No