


NATV12-PP

Galet de roulement

Yoke type track rollers NATV...-PP-A, single row needle roller bearings with particularly thick-walled outer ring, full complement needle roller set and an inner ring, axial guidance of outer ring is provided by the plastic axial plain washers and contact washers, three-stage sealing by plastic axial plain washer on both sides

Information technique

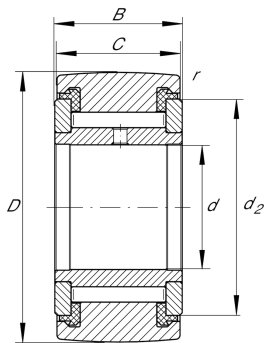

Votre alternative produit actuelle

joint	PP	Joint frottant des deux côtés
profile bague extérieure	IOP	Optimized INA-profile
dispositif de lubrification	IR	Via inner ring

dimensions principale & données de performance

d	12 mm	Alésage
D	32 mm	Diamètre extérieur
B	15 mm	Largeur, bague intérieure
C _{r w}	9.600 N	Charge dyn. de base, radiale
C _{0r w}	15.900 N	Charge stat. de base, radiale
C _{ur w}	2.210 N	Limite à la fatigue, radiale
n _{D G}	1.800 1/min	Vitesse pour une lubrification à la graisse
F _{0r per}	15.900 N	Charge radiale statique admissible
F _{r per}	14.900 N	Charge radial dynamique admissible sur bague extérieure
≈m	67,067 g	Poids

Dimensions

C	14 mm	Largeur, bague extérieure
d ₂	25 mm	Diamètre extérieur rondelle de butée
r _{min}	0,6 mm	Dimension minimum de chanfrein



Caractéristiques



Effort radial



Lubrification à vie, sans entretien



Lubrification à la graisse



Étanche des 2 côtés