




UBOOT8/13-NI-KIT

Ruland UBOOT8/13-NI-KIT, Universal Joint Boot for 0.495" (12.57mm) OD,
Nitrile, Double Bellows

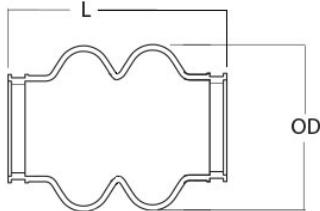

Description

Ruland UBOOT8/13-NI-KIT is a Nitrile boot cover kit for universal joints with an OD of 0.495" or 12.57mm. This boot cover protects the universal joint from unwanted contaminants such as dust and can be packed with grease for lubrication retention. It comes with zip ties that seat into grooves on each yoke ensuring a tight seal. UBOOT8/13-NI-KIT is made from Nitrile for durability and abrasion resistance that helps protect the boot from being damaged and grease leaking out or contaminants entering the joint. Nitrile also has high resistance to petroleum-based oils and fuels, silicone greases, hydraulic fluids, water, and alcohol which are commonly present in operating environments where this universal joint is used. It is designed to fit with single and double universal joints beginning with US8, USS8, UD8, UDS8, MUS13, and MUSS13.

Product Specifications

Boot Outer Diameter (OD)	0.95 in (24.1 mm)	Length (L)	0.880 in (22.4 mm)
Matching Joint Outer Diameter	0.495 in (12.6 mm)	Bellows	Double
Material Specification	Nitrile	Manufacturer	Belden Universal
Country of Origin	USA	Weight (lbs)	0.005000
UPC	634529289440	Tariff Code	8483.60.4000
UNSPC	25173810		
Note 1	Performance ratings are for guidance only. The user must determine suitability for a particular application.		