

572E Angled Tip Cutter

- Medium head for cutting horizontal or vertical
- Full flush cut
- For 22 awg wire and .010-.030 nickel ribbon



Cat No.	UPC No.	Packed	Length		Max. Cutting Dia.		Dimension "A"		Dimension "C"		Shelf Pack
			Inch	mm	Inch	mm	Inch	mm	Inch	mm	
572E	043127076817	Boxed	4.5	114	.024	0.6	.709	18	.256	6.5	1

575E, E575E Angled Tip Cutter


- Miniature angle cutter for delicate cutting applications
- Full flush cut
- For 22 awg and smaller wires



Cat No.	UPC No.	Packed	Length		Max. Cutting Dia.		Dimension "A"		Dimension "C"		Shelf Pack
			Inch	mm	Inch	mm	Inch	mm	Inch	mm	
575E	043127076879	Boxed	4.25	108	.024	0.6	.591	15	.157	5	1
*E575E	043127084522	Boxed	6	152	.024	0.6	.591	15	.157	5	1

582E, E582E Angled Tip Cutter

- Medium head size angle cutter
- Full flush cut
- For 20 awg wire and smaller also for nickel ribbon .010-.030
- 582E Length is 4.5" (114mm)
- E582E Length is 6.25" (159mm)

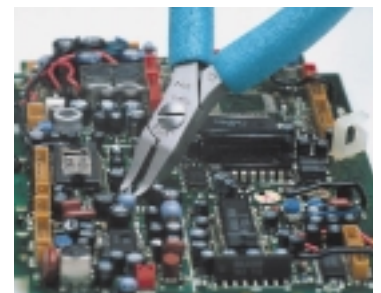

Cat No.	UPC No.	Packed	Max. Cutting Dia.		Dimension "A"		Dimension "B"		Dimension "C"		Dimension "D"		Dimension "E"		Shelf Pack
			Inch	mm	Inch	mm	Inch	mm	Inch	mm	Inch	mm			
582E	043127076923	Boxed	.047	1.2	.787	20	.256	6.5	.276	7	.060	1.5	.197	5	1
*E582E	043127084522	Boxed	.047	1.2	.787	20	.256	6.5	.276	7	.060	1.5	.197	5	1

RS 239-4010

* Ergonomic version