




LK6FSTL

Full shielded CAT6 tool less RJ45 modular jack - Link+ range



+ BENEFITS

- Tool less CAT6 RJ45 modular jack
- Link compliant
- Low depth

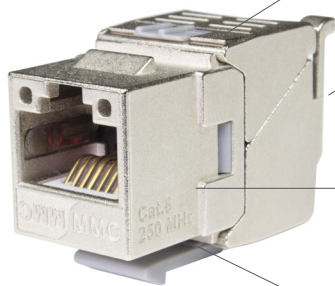

Connector «link certified»

Compact connector with a depth of 28.25mm : suitable to a big part of wall boxes and faceplates of the market

Optimized printed circuit to improve the ration S/N in high frequency


Keystone format

Wiring cap offering color code TIA 568B

Translucent wiring cap to facilitate the visual cabling inspection

Termination through wiring cap equipped with an insert to facilitate the wire management reduce the untwisted lenght : optimisation of the NEXT value

Two wings to offer a simple connector locking (no loose part)

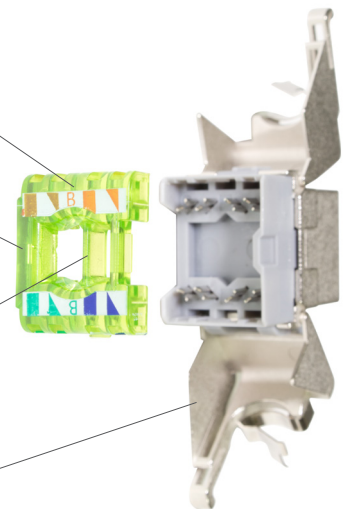



LK6FSTL

Full shielded CAT6 tool less RJ45 modular jack - Link+ range

PERFORMANCES

CONNECTOR	SYSTEM
IEC 60603-7-5 CAT6	TIA 568-C.2 CAT6
FCC Part 68 subpart F	ISO 11801 Ed2.2 Class E
TIA 570-B	EN 50173-1
UL 18663	IEEE 802.3af & at (PoE / PoEP)

TECHNICAL PROPERTIES

IDC :	Bronze + Platine / Cu + SnPb 80μ
Solid and flexible wires	AWG 26 to AWG 23
Maximum insulation diameter :	1.3 mm
Maximum cable diameter :	8.5mm
Contacts :	Bronze, Platine Ni and Au 1.2μm
Body	ZAMAC
Color code	568 B

ELECTRICAL PROPERTIES



Contact resistance :	< 20 mΩ IEC 60512-2-1 Test 2a
Input/Output resistance :	< 200mΩ IEC 60512-2-1 Test 2a
Insulation resistance :	> 500MΩ @100V DC IEC 60512-3-1 Test 3a
Voltage :	> 1000V DC contact to contact > 1500V DC contact to ground (IEC 60512-4-1 Test 4a Method A)
Insertion cycle :	> 1000
Operating voltage :	< 72V DC
Capacity of power :	< 30W
Operating Temperature :	-40°C to +70°C



LK6FSTL

Full shielded CAT6 tool less RJ45 modular jack - Link+ range

3D DRAWINGS

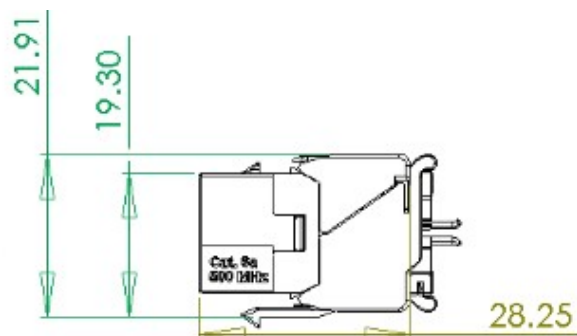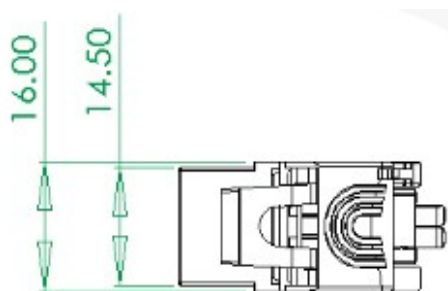








ORDERING INFORMATION

P/N	DESCRIPTION	PACKING
LK6FSTL8	Tool less full shielded CAT6 RJ45 modular jack - Link+ range	8

Individual polybag
Weight 20g



ORDER	PACKING LEVEL	QUANTITY	PICTURE PACKING
<p>If quantity is nx8 pcs</p> 	<p>Transparent polybag 140x200 Total Weight 160g</p>	8 pcs	
<p>If quantity is nx48 pcs</p> 	<p>Printed carton box 230x230x70 Total Weight 1.1Kg</p>	48 pcs	
<p>If quantity is nx480 pcs</p> 	<p>Neutral brown carton 750x237x250 Total Weight 12Kg</p>	480 pcs	
<p>If quantity is nx9600 pcs</p> 	<p>Wood pallet 800x1200x1100 Total Weight 241Kg</p>	9600 pcs	