



# RS Pro 3.5mm Pitch Pluggable Rising Clamp Terminal

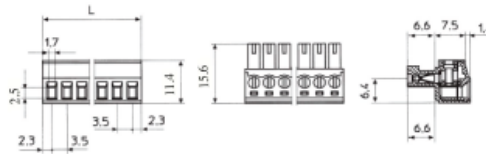


## Female connector

TYPE NO.	POLES	LENGTH
8970998	2	7mm
8971001	3	10.5mm
8971004	4	14mm
8971008	5	17.5mm
8971017	6	21mm
8971010	7	24.5mm
8971014	8	28mm
8971023	9	31.5mm

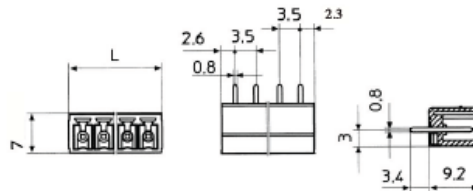

## PCB mounting male vertical (closed ended)

TYPE NO.	POLES	LENGTH
8971026	2	8.4mm
8971020	3	11.9mm
8971039	4	15.4mm
8971032	5	18.9mm
8971036	6	22.4mm
8971045	7	25.9mm
8971048	8	29.4mm
8971042	9	32.9mm

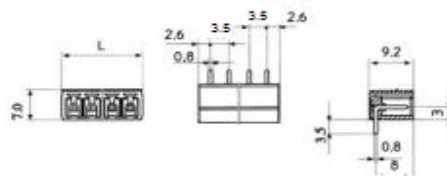

## PCB mounting male horizontal (closed ended)

TYPE NO.	POLES	LENGTH
8971051	2	8.4mm
8971054	3	11.9mm
8971058	4	15.4mm
8971067	5	18.9mm
8971060	6	22.4mm
8971064	7	25.9mm
8971073	8	29.4mm
8971076	9	32.9mm