


Part Number:0150200233

Status:Active

Overview:FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers

Description:0.50mm Pitch Premo-Flex FFC Jumper, Same Side Contacts (Type A), 102.00mm Cable Length, Gold (Au) Plating, 22 Circuits

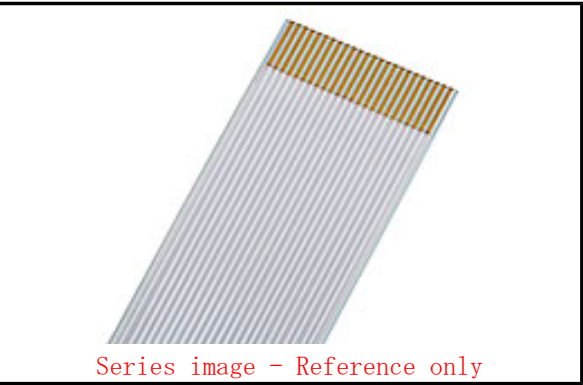

Documents:	
図面 (PDF)	Datasheet (PDF)
製品仕様書 PS-15020-001-001 (PDF)	RoHS Certificate of Compliance (PDF)
一般コメント	
Crimp Quality Equipment	Contacts on the same side, Type A
概要	Yes
	FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers
製品名	Premo-Flex FFC Jumper
UPC	884982176959
機械的性能/材質	
ケーブル長	102.00mm
極数 (実装)	22
Contact Layout Type	A (same side)
材質 - 嵌合部メッキ	金
Net Weight	0.742/g
梱包形態	ポリ袋
ピッチ - 嵌合部 (インチ)	0.50mm
使用温度範囲	-40° to +105° C
電線サイズ (AWG)	N/A
ケーブル種別	FFC
電気的性能	
最大定格電流	0.5A
最大定格電圧	60V AC
参考情報	
図面・仕様書情報	
製品仕様書	PS-15020-001-001
製品図面	SD-15020-001-001

EU ELV
Not Relevant

EU RoHS
Compliant

REACH SVHC
Not Reviewed

Halogen-Free
Status
Not Reviewed

For more information, please visit
Contact US

China ROHS
ELV

Green Image
Not Relevant

RoHS Phthalates
Not Contained

Search Parts in this Series

15020 Series

Mates With

Easy-On FFC/FPC Connector:

5034802200 , 5051102291 , 524352271 ,
524372271 , 5019512210 , 5019512230 ,
5019512250 , 525592253