
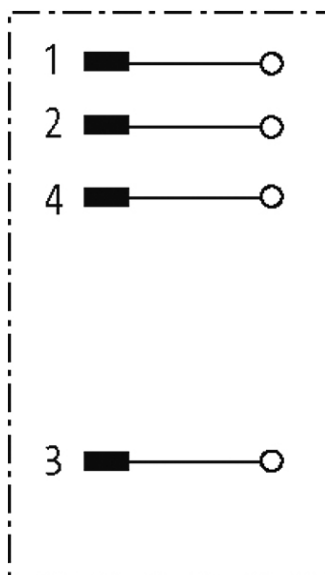


**M12 MALE Y-DISTR. 0° WIREABLE SCREW TERM.**4-pol. max.0,75mm<sup>2</sup>

Plastic housings with good resistance against chemicals and oils. The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)**Illustration**

Male

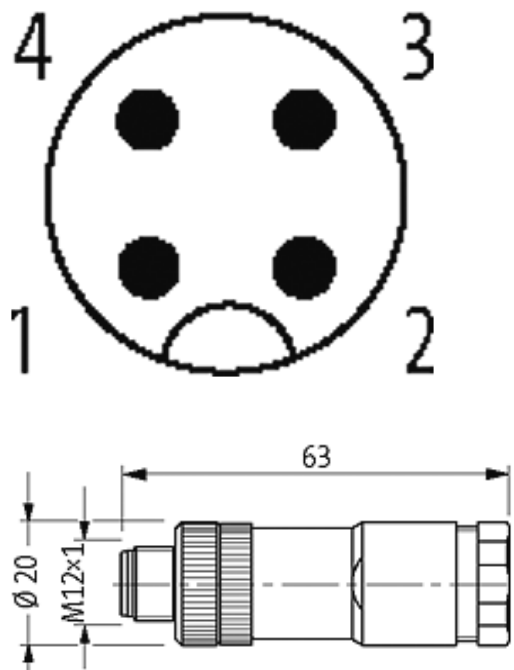

Product may differ from Image

**Form**

Form 12781

**Technical Data**

|                               |  |
|-------------------------------|--|
| Operating voltage             | max. 250 V AC/DC                       |
| Operating current per contact | max. 4 A                               |
| Connection cross section      | max. 0.75 mm <sup>2</sup>              |
| Sealing range (cable Ø)       | 2.1...3/4...5 mm (2 cable entries)     |
| Protection                    | IP67 inserted and tightened (EN 60529) |

**General data**

|                      |              |
|----------------------|--------------|
| Temperature range    | -25...+85 °C |
| Dimensions H x W x D | 63x20x20 mm  |

**Commercial data**

|                        |               |
|------------------------|---------------|
| country of origin      | DE            |
| customs tariff number  | 85369010      |
| EAN                    | 4048879201629 |
| eClass                 | 27279221      |
| minimum order quantity | 1             |