

# SAC-HZ-5P-M12MS/1,5-542/M12FSSH - Sensor/actuator cable



1409578

<https://www.phoenixcontact.com/in/products/1409578>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Sensor/actuator cable, 5-position, PVC, yellow, shielded, Plug straight M12, coding: A, on  
Socket straight M12, coding: A, cable length: 1.5 m



## Commercial data

|                                      |                                |
|--------------------------------------|--------------------------------|
| Item number                          | 1409578                        |
| Packing unit                         | 1 pc                           |
| Minimum order quantity               | 10 pc                          |
| Note                                 | Made to order (non-returnable) |
| Sales key                            | BF1                            |
| Product key                          | AF1IGC                         |
| GTIN                                 | 4055626018348                  |
| Weight per piece (including packing) | 115.4 g                        |
| Weight per piece (excluding packing) | 22.22 g                        |
| Customs tariff number                | 85444290                       |
| Country of origin                    | US                             |

# SAC-HZ-5P-M12MS/1,5-542/M12FSSH - Sensor/actuator cable



1409578

<https://www.phoenixcontact.com/in/products/1409578>

## Technical data

### Notes

|         |                                                                                                     |
|---------|-----------------------------------------------------------------------------------------------------|
| General | These cable assemblies are UL/cUL listed for use in Class I, Division 2 (CID2) hazardous locations. |
|---------|-----------------------------------------------------------------------------------------------------|

### Product properties

|                      |                                     |
|----------------------|-------------------------------------|
| Product type         | Sensor/actuator cable               |
| Application          | U.S. cables for hazardous locations |
| Number of positions  | 5                                   |
| No. of cable outlets | 1                                   |
| Shielded             | yes                                 |
| Coding               | A                                   |

### Insulation characteristics

|                      |    |
|----------------------|----|
| Overvoltage category | II |
| Degree of pollution  | 3  |

### Material specifications

|                                        |                                             |
|----------------------------------------|---------------------------------------------|
| Flammability rating according to UL 94 | HB                                          |
| Seal material                          | NBR                                         |
| Material of grip body                  | TPU, hardly inflammable, self-extinguishing |
| Contact material                       | CuSn                                        |
| Contact surface material               | Ni/Au                                       |
| Contact carrier material               | TPU GF                                      |
| Material for screw connection          | Zinc die-cast, nickel-plated                |
| Outer sheath, material                 | PVC                                         |

### Electrical properties

|                       |                            |
|-----------------------|----------------------------|
| Insulation resistance | $\geq 100 \text{ M}\Omega$ |
| Nominal voltage $U_N$ | 48 V AC                    |
|                       | 60 V DC                    |
| Nominal current $I_N$ | 4 A                        |

### Signaling

|                        |    |
|------------------------|----|
| Status display         | no |
| Status display present | No |

### Connection data

|                      |                        |
|----------------------|------------------------|
| Conductor connection |                        |
| Tightening torque    | 0.4 Nm (M12 connector) |

### Connector

# SAC-HZ-5P-M12MS/1,5-542/M12FSSH - Sensor/actuator cable



1409578

<https://www.phoenixcontact.com/in/products/1409578>

## Connection 1

|                     |                   |
|---------------------|-------------------|
| Type                | Plug straight M12 |
| Number of positions | 5                 |
| Coding type         | A                 |


## Connection 2

|                     |                     |
|---------------------|---------------------|
| Type                | Socket straight M12 |
| Number of positions | 5                   |
| Coding type         | A                   |

## Cable/line

|              |       |
|--------------|-------|
| Cable length | 1.5 m |
|--------------|-------|

## PVC yellow 105 °C [542]
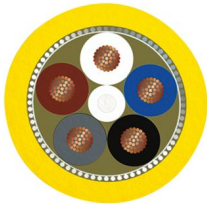
|                                               |                                                                                      |
|-----------------------------------------------|--------------------------------------------------------------------------------------|
| Dimensional drawing                           |  |
| Cable weight                                  | 57 kg/km                                                                             |
| UL AWM Style                                  | 2517 (105 °C / 300 V)                                                                |
| Number of positions                           | 5                                                                                    |
| Shielded                                      | yes                                                                                  |
| Cable type                                    | PVC yellow 105 °C [542]                                                              |
| Conductor structure signal line               | 30x 1.30 mm                                                                          |
| AWG signal line                               | 22                                                                                   |
| Wire diameter incl. insulation                | 1.27 mm ±0.03 mm                                                                     |
| External cable diameter                       | 5.90 mm ±0.2 mm                                                                      |
| Outer sheath, material                        | PVC                                                                                  |
| External sheath, color                        | yellow                                                                               |
| Conductor material                            | Tin-plated Cu litz wires                                                             |
| Material, filler                              | PP                                                                                   |
| Material wire insulation                      | PVC                                                                                  |
| Single wire, color                            | brown, blue, black, white, gray                                                      |
| Overall twist                                 | 5 wires around filler to the core                                                    |
| Optical shield covering                       | 85 %                                                                                 |
| Max. conductor resistance                     | max. 50.5 Ω/km (20 °C)                                                               |
| Insulation resistance                         | ≥ (550 M Ohms/m @ 500V)                                                              |
| Nominal voltage, cable                        | 300 V                                                                                |
| Minimum bending radius, flexible installation | 12 x D                                                                               |

# SAC-HZ-5P-M12MS/1,5-542/M12FSSH - Sensor/actuator cable



1409578

<https://www.phoenixcontact.com/in/products/1409578>

|                                               |                                                 |
|-----------------------------------------------|-------------------------------------------------|
| Smallest bending radius, movable installation | 71 mm                                           |
| Flame resistance                              | FT4                                             |
| Other resistance                              | UV resistant                                    |
| Special properties                            | UL standards PLTC and ITC                       |
| Ambient temperature (operation)               | -30 °C ... 105 °C (cable, fixed installation)   |
|                                               | -5 °C ... 105 °C (Cable, flexible installation) |

## Environmental and real-life conditions

### Ambient conditions

|                                 |                                  |
|---------------------------------|----------------------------------|
| Degree of protection            | IP65                             |
|                                 | IP67                             |
| Ambient temperature (operation) | -25 °C ... 90 °C (Plug / socket) |

## Approvals

### Conformity/Approvals

|                  |                                    |
|------------------|------------------------------------|
| UL, USA / Canada | Class I, Div. 2, Groups A, B, C, D |
|------------------|------------------------------------|

## Standards and regulations

|                          |                 |
|--------------------------|-----------------|
| Standard designation     | M12 connector   |
| Standards/specifications | IEC 61076-2-101 |

# SAC-HZ-5P-M12MS/1,5-542/M12FSSH - Sensor/actuator cable




1409578

<https://www.phoenixcontact.com/in/products/1409578>


## Drawings

Circuit diagram

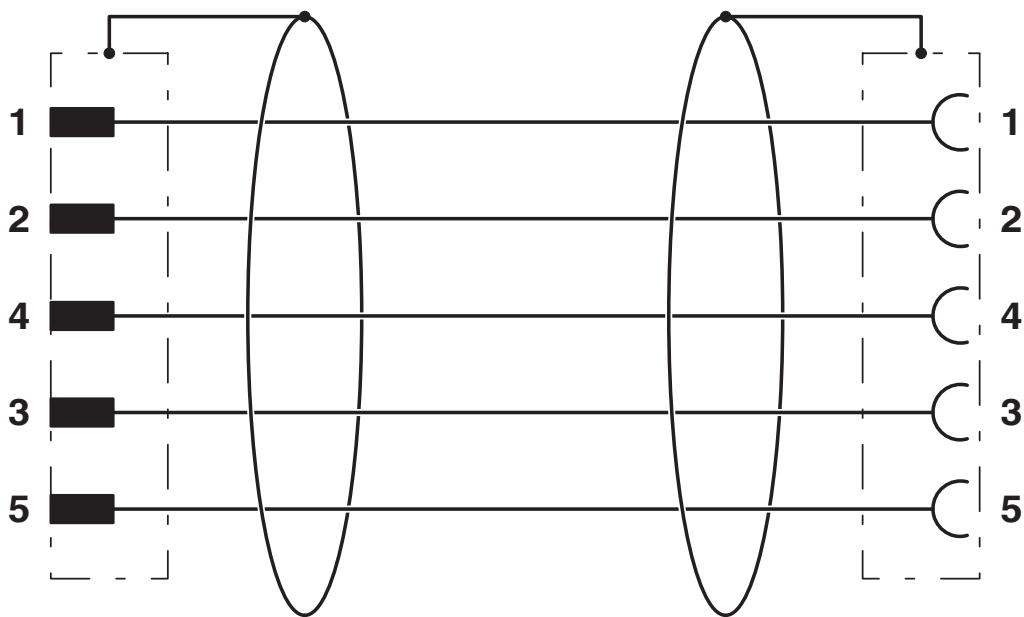

Contact assignment of the M12 plug and the M12 socket

Schematic diagram

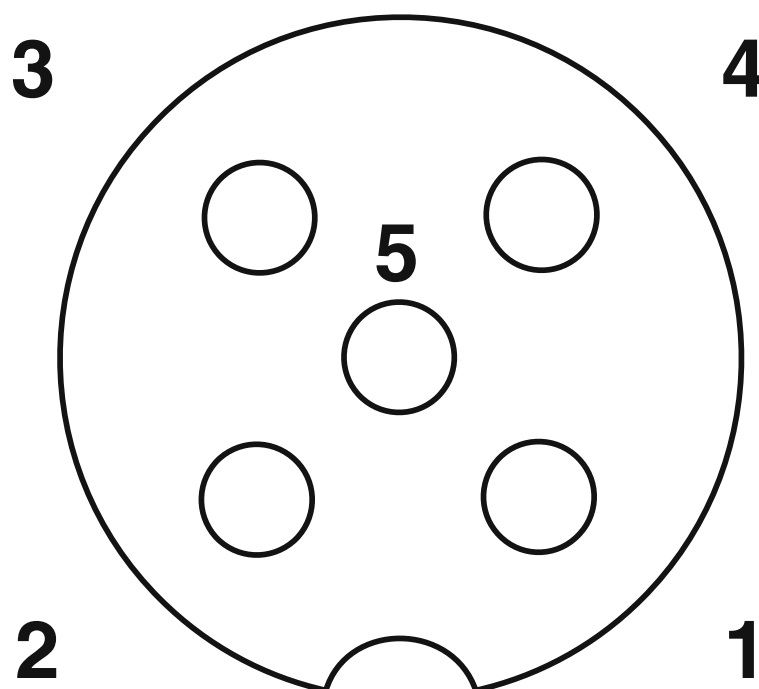


Pin assignment M12 socket, 5-pos., A-coded, socket side view

# SAC-HZ-5P-M12MS/1,5-542/M12FSSH - Sensor/actuator cable

1409578


<https://www.phoenixcontact.com/in/products/1409578>

Dimensional drawing

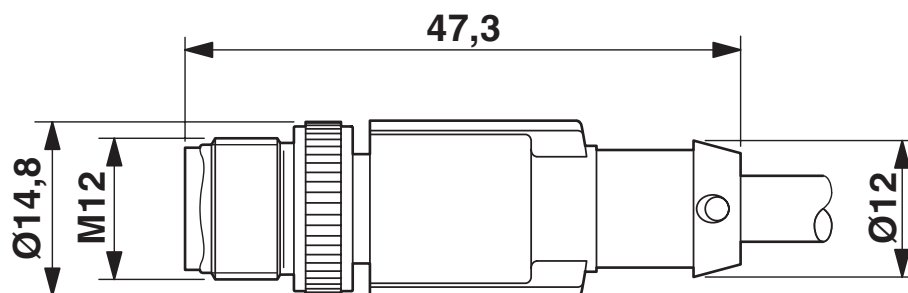


Plug, M12 x 1, straight, shielded

Dimensional drawing

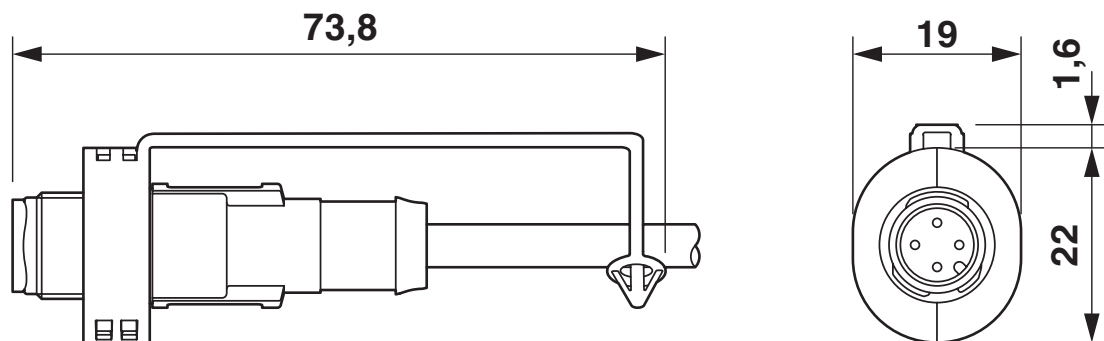

EXCLIP mounted plug

Dimensional drawing

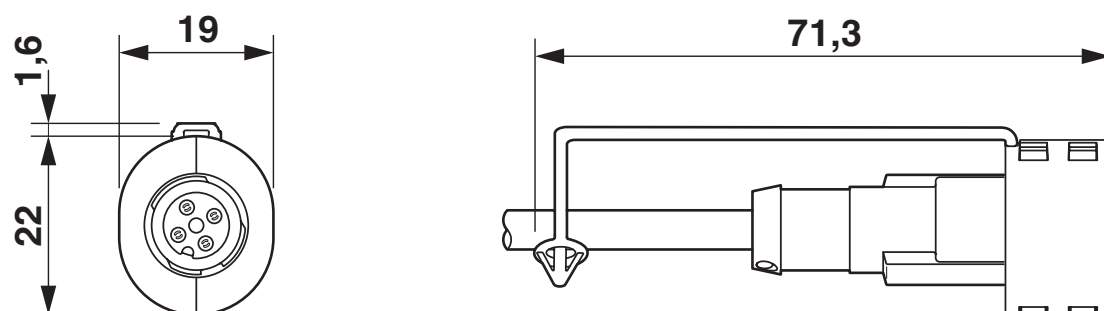

EXCLIP mounted plug


# SAC-HZ-5P-M12MS/1,5-542/M12FSSH - Sensor/actuator cable



1409578

<https://www.phoenixcontact.com/in/products/1409578>

Schematic diagram

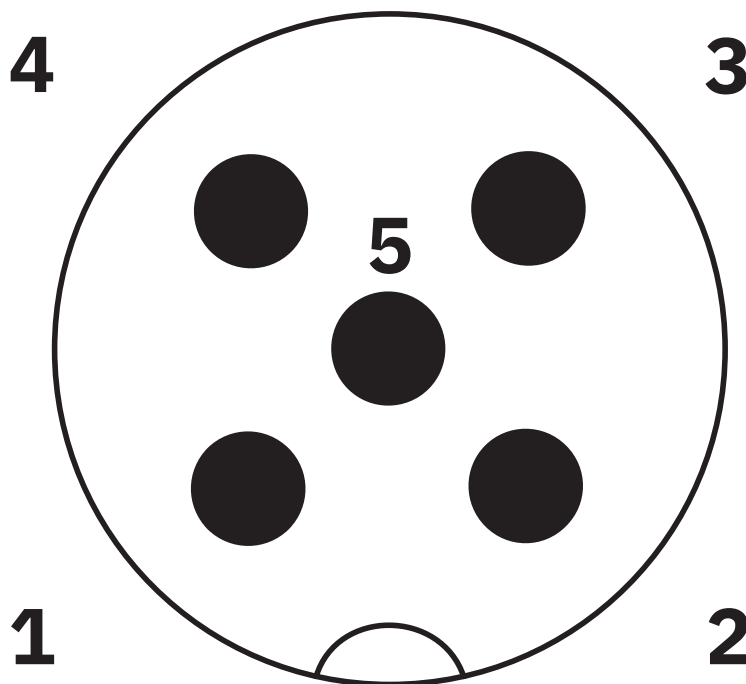


Pin assignment M12 male connector, 5-pos., A-coded, male side

# SAC-HZ-5P-M12MS/1,5-542/M12FSSH - Sensor/actuator cable

1409578


<https://www.phoenixcontact.com/in/products/1409578>

Dimensional drawing

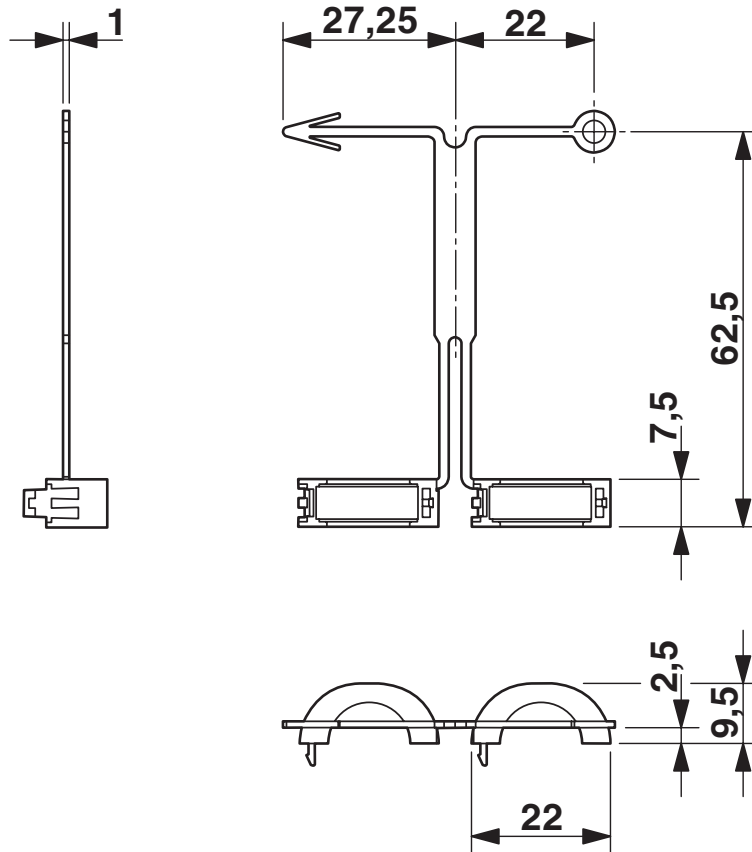

EXCLIP plug

Dimensional drawing

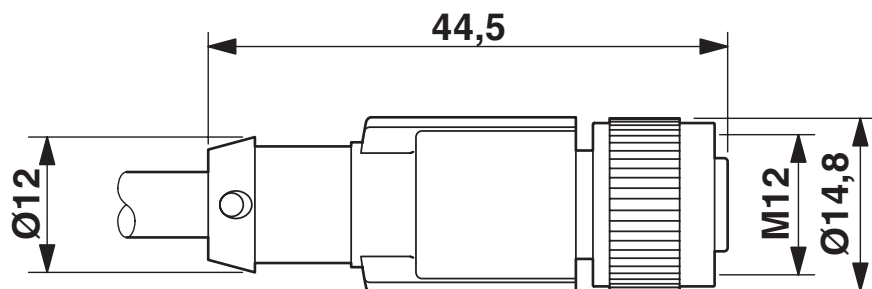

M12 x 1 socket, straight, shielded




# SAC-HZ-5P-M12MS/1,5-542/M12FSSH - Sensor/actuator cable

1409578

<https://www.phoenixcontact.com/in/products/1409578>

Dimensional drawing

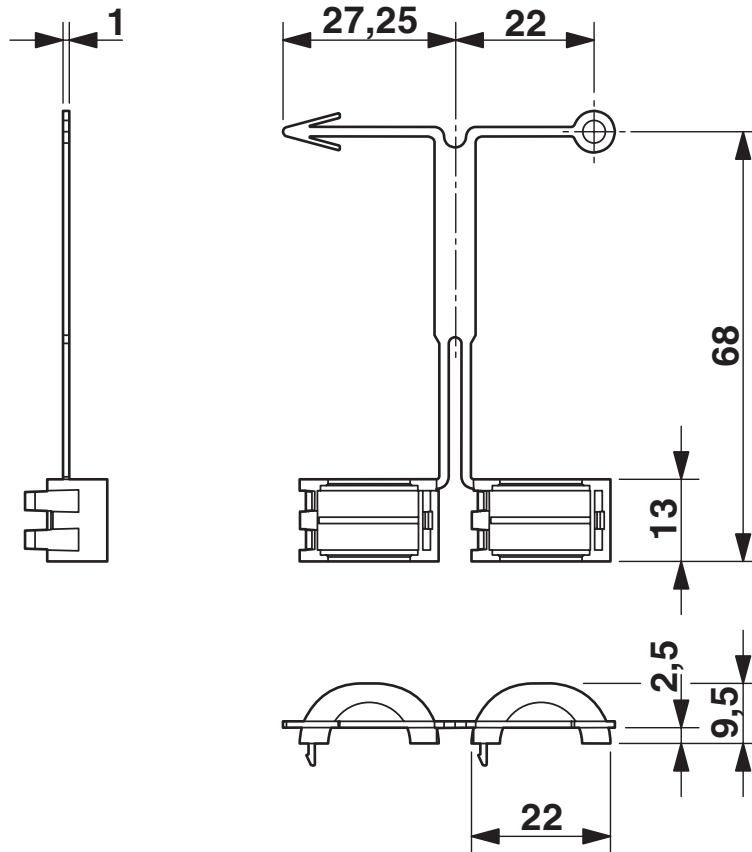

EXCLIP socket

# SAC-HZ-5P-M12MS/1,5-542/M12FSSH - Sensor/actuator cable



1409578

<https://www.phoenixcontact.com/in/products/1409578>

## Approvals

To download certificates, visit the product detail page: <https://www.phoenixcontact.com/in/products/1409578>



### EAC-RoHS

Approval ID: RU D-DE.HB35.B.00387



### cUL Listed

Approval ID: FILE E 359524

|  | Nominal voltage $U_N$ | Nominal current $I_N$ | Cross section AWG | Cross section $\text{mm}^2$ |
|--|-----------------------|-----------------------|-------------------|-----------------------------|
|  | 150 V                 | 4 A                   | -                 | -                           |



### UL Listed

Approval ID: FILE E 359524

|  | Nominal voltage $U_N$ | Nominal current $I_N$ | Cross section AWG | Cross section $\text{mm}^2$ |
|--|-----------------------|-----------------------|-------------------|-----------------------------|
|  | 150 V                 | 4 A                   | -                 | -                           |

### cULus Listed

# SAC-HZ-5P-M12MS/1,5-542/M12FSSH - Sensor/actuator cable



1409578

<https://www.phoenixcontact.com/in/products/1409578>

## Classifications

### ECLASS

|             |          |
|-------------|----------|
| ECLASS-11.0 | 27060311 |
| ECLASS-12.0 | 27060311 |
| ECLASS-13.0 | 27060311 |

### ETIM

|          |          |
|----------|----------|
| ETIM 9.0 | EC001855 |
|----------|----------|

### UNSPSC

|             |          |
|-------------|----------|
| UNSPSC 21.0 | 26121600 |
|-------------|----------|

# SAC-HZ-5P-M12MS/1,5-542/M12FSSH - Sensor/actuator cable



1409578  
<https://www.phoenixcontact.com/in/products/1409578>

## Environmental product compliance

|                                         |                                          |
|-----------------------------------------|------------------------------------------|
| EU RoHS                                 |                                          |
| Fulfills EU RoHS substance requirements | Yes, No exemptions                       |
| China RoHS                              |                                          |
| Environment friendly use period (EFUP)  | EFUP-E                                   |
|                                         | No hazardous substances above the limits |
| EU REACH SVHC                           |                                          |
| REACH candidate substance (CAS No.)     | No substance above 0.1 wt%               |

# SAC-HZ-5P-M12MS/1,5-542/M12FSSH - Sensor/actuator cable



1409578

<https://www.phoenixcontact.com/in/products/1409578>

## Accessories

### PROT-M12 FS-PA-CHAIN - Sealing cap

1430873

<https://www.phoenixcontact.com/in/products/1430873>

M12 sealing cap made of plastic with fixing band, for sensor cables, for free M12 plugs



### SAC-M12-EXCLIP-M - Locking clip

1558988

<https://www.phoenixcontact.com/in/products/1558988>

Locking clip for the pin side of sensor/actuator cables with M12 connector and M12 connectors for assembly, for knurl diameter: 15 mm or for Allen key with a wrench size of 14 mm, prevents the disconnection of plug-in connections without tools



# SAC-HZ-5P-M12MS/1,5-542/M12FSSH - Sensor/actuator cable



1409578

<https://www.phoenixcontact.com/in/products/1409578>

## PROT-M12 MS-PA-CHAIN - Screw plug

1430899

<https://www.phoenixcontact.com/in/products/1430899>

M12 sealing cap with fixing band, for sensor cables, for free M12 sockets



---

## SAC-M12-EXCLIP-F - Locking clip

1558991

<https://www.phoenixcontact.com/in/products/1558991>

Locking clip for the socket side of sensor/actuator cables with M12 connector and M12 connectors for assembly, for knurl diameter: 15 mm or for Allen key with a wrench size of 14 mm, prevents the disconnection of plug-in connections without tools



# SAC-HZ-5P-M12MS/1,5-542/M12FSSH - Sensor/actuator cable



1409578

<https://www.phoenixcontact.com/in/products/1409578>

## TSD 04 SAC - Torque screwdriver

1208429

<https://www.phoenixcontact.com/in/products/1208429>



Torque screwdriver, with preset torque of 0.4 Nm and 4 mm hexagonal drive for M12 connectors

---

## TSD-M 1,2NM - Torque screwdriver

1212224

<https://www.phoenixcontact.com/in/products/1212224>



Torque screw driver, accuracy as per EN ISO 6789 standard, adjustable from 0.3 - 1.2 Nm

# SAC-HZ-5P-M12MS/1,5-542/M12FSSH - Sensor/actuator cable



1409578

<https://www.phoenixcontact.com/in/products/1409578>

## TSD-M SAC-BIT ADAPTER - Adapter insert

1212600

<https://www.phoenixcontact.com/in/products/1212600>



Adapter bit for TSD-M...torque tools, E6.3-1/4" drive with 4 mm hexagon to accommodate SAC bits

## SAC BIT M12-D15 - Tool

1208432

<https://www.phoenixcontact.com/in/products/1208432>



Nut for assembling sensor/actuator cables with M12 connector and M12 connectors for assembly, with a knurl diameter of 15 mm, for 4 mm hexagonal drive

Phoenix Contact 2025 © - all rights reserved

<https://www.phoenixcontact.com>

PHOENIX CONTACT (I) Pvt. Ltd.

A-58/2, Okhla Industrial Area, Phase - II, New Delhi-110 020

+91.1275.71420

[info@phoenixcontact.co.in](mailto:info@phoenixcontact.co.in)