



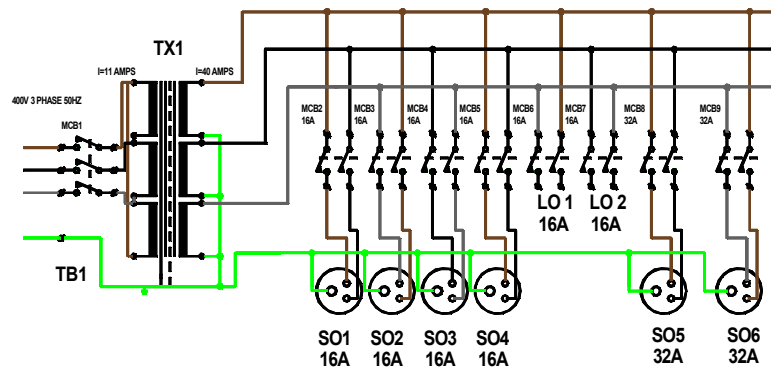

RS Pro Datasheet

Stock No: 1249719

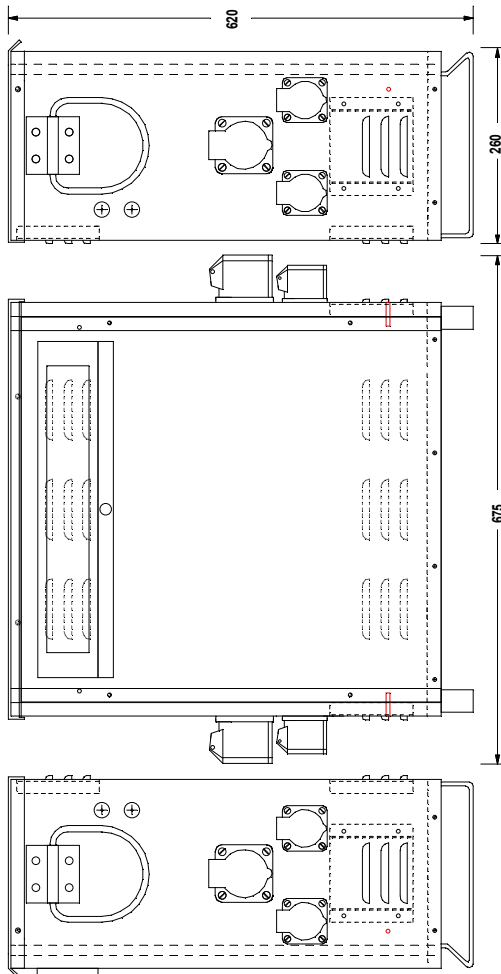

ELECTRICAL LAYOUT

SITE TRANSFORMER

INPUT	400V 3 PHASE 50/60Hz
OUTPUT	110V LINE - LINE STAR POINT EARTHED
RATING	7.5kVA CONTINUOUS
VECTOR Gp	DYN11
OUTPUT SOCKETS	2 x 32A BSEN60309 4 x 16A BSEN60309 2 x 16A LIGHTING OUTLETS
PROTECTION	
INPUT	1 x 3 POLE 16A MCB
OUTPUT	6 x 2 POLE 16A MCB'S 2 x 2 POLE 32A MCB'S
ENCLOSURE	SHEET STEEL IP44
COLOUR	YELLOW