

Ausrack Wall *anyX* 19" Wall Mounted Cabinets



INDEX

[Leaflet](#)

[Catalogue Information](#)

[Technical Drawings](#)

WEB LINKS

[Ausrack Wall *anyX* – Information Page](#)

[Ask a question / Send us an enquiry](#)

[Information about B&R](#)

[Local Sales Team Phone Numbers](#)

Features

- EIA-310-D standards compliant
- Flexible mounting with swing frame options
- Vented top to suit 2 fan units
- Reversible safety glass door with keylock
- Key lockable / removable side panels
- Adjustable 19" mounting rails
- Lockable swing frame (on selected models)
- Fixed shelf (2 on 18RU)
- Cable cutouts on enclosure and swing frame with easy-to-remove gland plates



OVERVIEW

A durable wall-mounted cabinet for use in small networking applications. They are easy-to-install and provide maximum accessibility for maintenance, with rear swing frame on selected models allowing easy access to the rear of the enclosure.

MATERIALS

- Body – SPCC rolled steel
- Body thickness – 1.2mm
- Surface finish – Powdercoated textured matt black

APPLICATION

Typical applications include housing network equipment such as patch panels, modems and routers.

INCLUSIONS

- Lockable swing frame (on selected models)
- Safety glass keylockable door
- Adjustable 19" mounting rails
- Key locks on front and side panels
- Fixed shelf



Ausrack Wall *anyX* – SPCC Rolled Steel

SELECTION GUIDE

Catalogue No.	RU	Dimensions (mm)		Enclosure Depth (mm)	Swing Frame	Total Depth (mm)	Fixed Shelf	Weight (kg)
		Height	Width					
ARWX6U450NF	6	370	600	450	–	450	1	18.0
ARWX6U450	6	370	600	450	100mm	550*	1	23.0
ARWX9U450	9	500	600	450	100mm	550*	1	27.0
ARWX12U450NF	12	635	600	450	–	450	1	24.0
ARWX12U450	12	635	600	450	100mm	550*	1	32.0
ARWX18U450	18	905	600	450	100mm	550*	2	39.0

* Includes depth of swing frame 100mm

ACCESSORIES

Product	Description	Catalogue No.
Fan unit	2 fan unit	ARWX2F
	6 x 10A outlets, 10A plug	ARPRH61010
Power rails – horizontal (10A outlets only) SAA	6 x 10A outlets, 15A plug	ARPRH61015
	10 x 10A outlets, 10A plug	ARPRH101010
	10 x 10A outlets, 15A plug	ARPRH101015
Horizontal cable management	1RU	ARPCM1U
Shelves – fixed	450mm	ARWX450FS
Shelves – cantilever	450mm	ARWX450CS
Spare key	Door, swing frame	ARFXKEYR
Cage Nuts	Pack of 50	ARCN




Fan unit – 2 fan unit



Horizontal power rails



Cable management

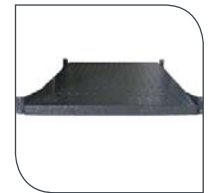

Shelf – fixed



Shelf – cantilever

National Sales

P 1300 Enclosures (1300 362 567)

F 1300 796 599

E sales@brenclosures.com.au

brenclosures.com.au

Queensland P +61 7 3714 1111

Nth Queensland P +61 7 4727 1900

New South Wales P +61 2 9915 9555

Newcastle P +61 2 4961 4433


Victoria P +61 3 9552 0552

South Australia P +61 8 8417 6222


Western Australia P +61 8 6310 4777




Technical Drawings

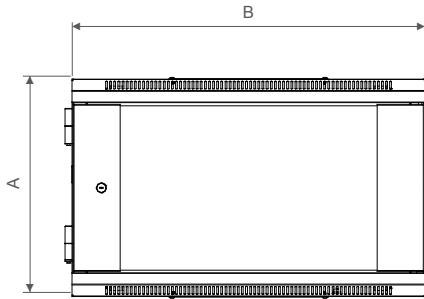


Front View

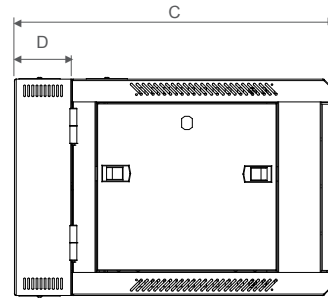

Side View

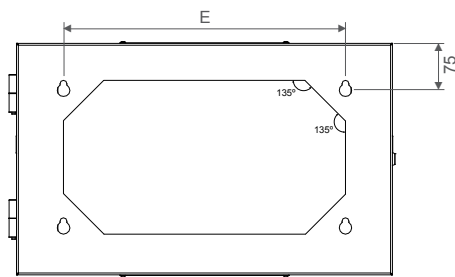

Rear View

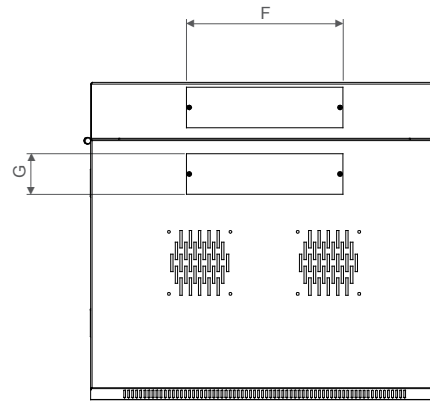

Top View

Catalogue No.	Dimensions (mm)						
	External		Mounting Centres		Entry		
	A	B	C	D	E	F	G
ARWX6U450NF	370	600	450	-	450	270	65
ARWX6U450	370	600	550	98	450	270	65
ARWX9U450	500	600	550	98	450	270	65
ARWX12U450NF	635	600	450	-	450	270	65
ARWX12U450	635	600	550	98	450	270	65
ARWX18U450	905	600	450	98	450	270	65