



Double hexagon Metric, 7800DM

Sockets Double Hexagon Metric

DIN 3124/ISO 2725.

1/2" 12.5 DIN 3120/ISO 1174.






Finish: nickel and chrome-plated, fine-polished.

Material: CHROME-EXTRA.

With Dynamic-Drive-Profile.

SB = Retail packed on a plastic info card.



				L mm	D1 mm	D2 mm 
7800DM-8	1830854	10	8	38	12.9	22.0 42
7800DM-9	1830861	10	9	38	14.2	22.0 42
7800DM-10	1096991	10	10	38	15.4	22.0 51
7800DM-11	1097011	10	11	38	16.6	22.0 51
7800DM-12	1097035	10	12	38	17.9	22.0 51
7800DM-13	1097059	10	13	38	19.1	22.0 56
7800DM-14	1097073	10	14	38	20.4	22.0 56
7800DM-15	1097097	10	15	38	21.6	22.0 64
7800DM-16	1097110	10	16	38	22.9	22.0 64
7800DM-17	1097134	10	17	38	24.1	23.0 72
7800DM-18	1097158	10	18	38	25.4	23.5 76
7800DM-19	1097172	10	19	38	26.6	24.0 80
7800DM-20	1097196	5	20	38	27.9	24.5 81
7800DM-21	1097219	5	21	39	29.1	25.0 102
7800DM-22	1097233	5	22	39	30.4	25.5 109
7800DM-23	1097257	5	23	40	31.6	26.0 109
7800DM-24	1097271	5	24	41	32.9	26.5 121
7800DM-25	1097295	5	25	42	34.1	27.0 124
7800DM-26	1097318	5	26	43	35.4	28.0 136
7800DM-27	1097332	5	27	44	36.6	29.0 173
7800DM-28	1097356	5	28	45	37.9	27.6 173
7800DM-29	1097363	5	29	46	39.1	28.6 175
7800DM-30	1097370	5	30	47	40.4	29.5 189
7800DM-32	1097387	5	32	47	42.9	30.5 227
7800DM-36	1097400	1	36	57	50.0	42.0 315
SB7800DM-8	0104437	1	8	38	12.9	22.0 42
SB7800DM-9	0104444	1	9	38	14.2	22.0 42
SB7800DM-10	0104451	1	10	38	15.4	22.0 51
SB7800DM-11	0104468	1	11	38	16.6	22.0 51
SB7800DM-12	0104475	1	12	38	17.9	22.0 51
SB7800DM-13	0104482	1	13	38	19.1	22.0 56
SB7800DM-14	0104499	1	14	38	20.4	22.0 56
SB7800DM-15	0104505	1	15	38	21.6	22.0 64
SB7800DM-16	0104512	1	16	38	22.9	22.0 64
SB7800DM-17	0104529	1	17	38	24.1	23.0 72
SB7800DM-18	0104536	1	18	38	25.4	23.5 76

SB7800DM-19	0104543	1	19	38	26.6	24.0 80
SB7800DM-20	0104550	1	20	38	27.9	24.5 81
SB7800DM-21	0104567	1	21	39	29.1	25.0 102
SB7800DM-22	0104574	1	22	39	30.4	25.5 109
SB7800DM-23	0104581	1	23	40	31.6	26.0 109
SB7800DM-24	0104598	1	24	41	32.9	26.5 121
SB7800DM-25	0104604	1	25	42	34.1	27.0 124
SB7800DM-26	0104611	1	26	43	35.4	28.0 136
SB7800DM-27	0104628	1	27	44	36.6	29.0 173
SB7800DM-28	0104635	1	28	45	37.9	27.6 173
SB7800DM-29	0104642	1	29	46	39.1	28.6 175
SB7800DM-30	0104659	1	30	47	40.4	29.5 189
SB7800DM-32	0104666	1	32	47	42.9	30.5 227
SB7800DM-36	0104673	1	36	57	50.0	42.0 315



Double hexagon Inch, 7800DZ

Sockets Double Hexagon Inch

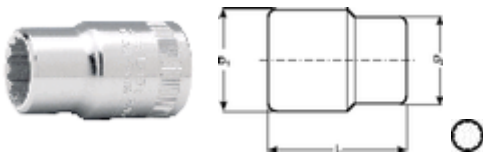
DIN 3124/ISO 2725.






1/2" 12.5 DIN 3120/ISO 1174.

Finish: nickel and chrome-plated, fine-polished.

Material: CHROME-EXTRA.

With Dynamic-Drive-Profile.



	 731415+			L mm	D1 mm	D2 mm 
7800DZ-3/8	1097431	5	3/8	38	14.5	22.0 41
7800DZ-7/16	1097448	5	7/16	38	16.6	22.0 46
7800DZ-1/2	1097455	5	1/2	38	18.8	22.0 51
7800DZ-9/16	1097462	5	9/16	38	20.8	22.0 53
7800DZ-19/32	1097479	5	19/32	38	21.6	22.0 56
7800DZ-5/8	1097486	5	5/8	38	22.9	22.0 65
7800DZ-11/16	1097493	5	11/16	38	24.7	23.0 75
7800DZ-3/4	1097509	5	3/4	38	26.6	24.0 76
7800DZ-25/32	1097516	5	25/32	38	27.9	24.5 85
7800DZ-13/16	1097523	5	13/16	39	28.7	25.0 92
7800DZ-7/8	1097530	5	7/8	39	30.7	25.5 99
7800DZ-15/16	1097554	5	15/16	41	32.7	26.0 120
7800DZ-1	1097561	5	1	42	34.7	27.5 139
7800DZ-1.1/16	1097578	1	1 1/16	44	36.6	29.0 142
7800DZ-1.1/8	1097585	1	1 1/8	46	38.6	29.0 157
7800DZ-1.3/16	1097592	1	1 3/16	47	40.4	29.0 178
7800DZ-1.1/4	1097608	1	1 1/4	47	42.3	30.5 185